



Brand of NTN corporation

## Technical data

### UKPE211H

Bearing units




Grey cast housing, radial insert ball bearing with adapter sleeve, seal with slinger

#### KIT CONTENT

UK211G2H, PE211

#### VISUAL (S)

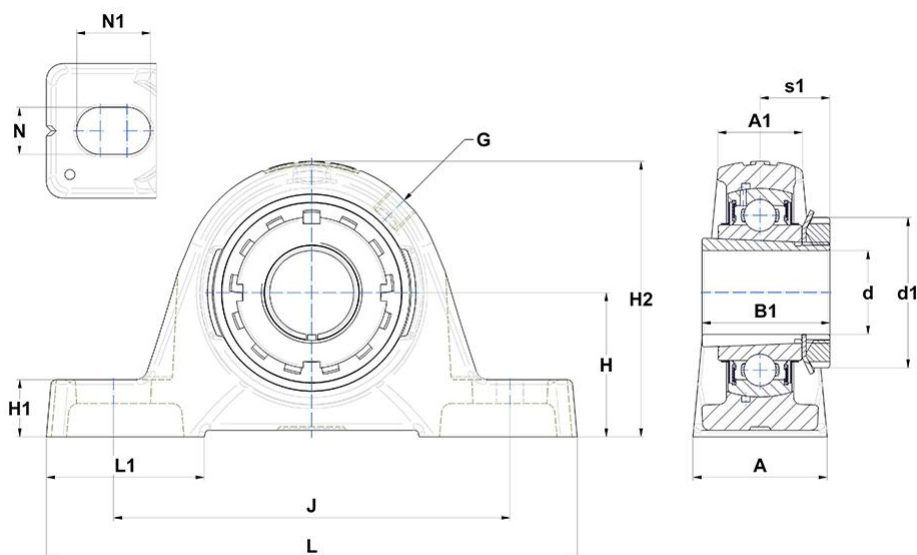

#### PRODUCT DEFINITION

|                                                                |       |
|----------------------------------------------------------------|-------|
| Brand                                                          | SNR   |
| A - Housing width                                              | 60 mm |
| A1 - Housing top width                                         | 35 mm |
| B - Width of Inner Ring                                        | 33 mm |
| d - Shaft diameter                                             | 50 mm |
| d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve | 75 mm |



#### NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

## PRODUCT DEFINITION

|                                                                        |          |
|------------------------------------------------------------------------|----------|
| <b>G - Grease fitting</b>                                              | R1/8"    |
| <b>H - Distance mounting base to centerline spheric. seating diam.</b> | 63,5 mm  |
| <b>H1 - Housing foot height</b>                                        | 22,5 mm  |
| <b>H2 - Housing height</b>                                             | 124,5 mm |
| <b>J - Mounting holes distance</b>                                     | 176 mm   |
| <b>L - Housing length</b>                                              | 222 mm   |
| <b>L1 - Housing foot length</b>                                        | 68 mm    |
| <b>N - Mounting hole dimension</b>                                     | 18 mm    |
| <b>N1 - Mounting hole length</b>                                       | 30 mm    |
| <b>s1 - Distance nut to middle of bearing raceway</b>                  | 29 mm    |

## PRODUCT PERFORMANCE

|                                   |             |
|-----------------------------------|-------------|
| <b>C - Dynamic load rating</b>    | 43550000 mN |
| <b>C0 - Static load rating</b>    | 29200000 mN |
| <b>Operating temperature min.</b> | 253,15 °K   |
| <b>Operating temperature max.</b> | 373,15 °K   |

## OTHER FEATURES

|                                   |         |
|-----------------------------------|---------|
| <b>Mass</b>                       | 3,51 kg |
| <b>Adapter sleeve designation</b> | H2311   |

