


Suction cup with connector OGVM-30X65-AV-N-G38F

Part number: 8210277

FESTO

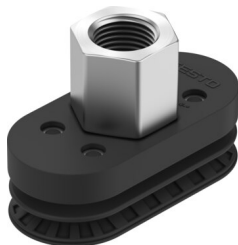

[PDF](#) General operating condition

Data sheet

Feature	Value
Height compensator for suction cup	7 mm
Min. workpiece radius	15 mm
Nominal size	6 mm
Suction cup size	30x65 mm
Suction cup volume	11.5 cm ³
Position of connection	On top
Mounting position	Any
Symbol	00991485
Suction cup shape	Oval protective bellows 1.5-fold
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Operating pressure	-13.775 psi ... 0 psi
Nominal operating pressure	-0.06 MPa
Nominal operating pressure	-0.6 bar
Nominal operating pressure	-8.7 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-A1/A2-L
Ambient temperature	-20 °C ... 80 °C
Holding force at nominal operating pressure	66 N
Vertical lateral force at nominal operatin pressure	104 N
Product weight	51 g
Type of mounting	Via vacuum port
Vacuum connection	Female thread G3/8
Colour	Black
Shore hardness	60 +/-5
Material screwed plug	Wrought aluminium alloy
Note on materials	RoHS compliant
Material suction cup	NBR