


Standard Analog Micrometers

External Micrometers


DIN 863

• for standard expectations

- drum and sleeve matt chrome finish
- frame hammer blow grey lacquered, with insulated handle
- carbide surfaces, lapped, spindle hardened and ground
- locking lever for quick and precise fixing
- with ratchet for constant measuring pressure
- from up 25 mm with setting gauge

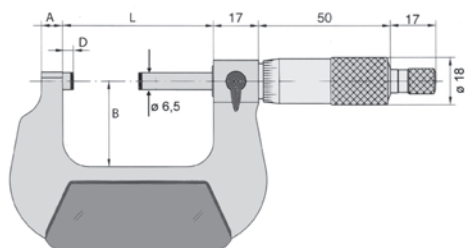

ART N° 231351 – 231354

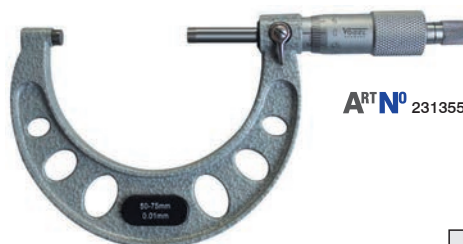

ART N° 231355 – 231358



ART N°	 mm	 mm	 ø mm	 mm	A mm	B mm	D mm	L mm	 max. mm	 CC
231351	0 – 25	0.01	18	0.5	6	24	3	32	0.004	on request
231352	25 – 50	0.01	18	0.5	8	32	3	57	0.004	on request
231353	50 – 75	0.01	18	0.5	8	45	3	82	0.005	on request
231354	75 – 100	0.01	18	0.5	8	57	3	107	0.005	on request
231355	100 – 125	0.01	18	0.5	8	70	3	133	0.006	on request
231356	125 – 150	0.01	18	0.5	8	82	3	158	0.006	on request
231357	150 – 175	0.01	18	0.5	8	95	5.5	183	0.007	on request
231358	175 – 200	0.01	18	0.5	8	107	5.5	209	0.007	on request


External Micrometer Sets

DIN 863

• for standard expectations

- drum and sleeve matt chrome finish
- frame hammer blow grey lacquered, with insulation plates
- carbide surfaces, lapped, spindle hardened and ground
- locking lever for quick and precise fixing
- with ratchet for constant measuring pressure
- with setting gauge

ART N° 232006

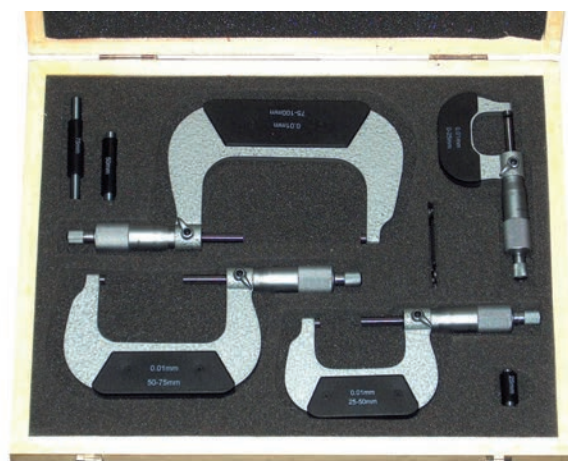

ART N° 232003 – 232004



ART N°	 mm	 mm	set content	 ø mm	 mm	spindle-ø mm	 CC
232003	0 – 75	0.01	3	18	0.5	6.5	on request
232004	0 – 100	0.01	4	18	0.5	6.5	on request
232006	0 – 150	0.01	6	18	0.5	6.5	on request
232107	150 – 300	0.01	6	18	0.5	6.5	on request
232108	0 – 300	0.01	12	18	0.5	6.5	on request
232109	100 – 200	0.01	4	18	0.5	6.5	on request