

Datasheet

## RS Pro P13.5s Filament Indicator Lamp, Clear, 4.8 V, 500 mA, 20h

RS Stock No: **105-174**



### Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton gas for high brightness. It has a voltage rating of 4.8 V and current rating of 500 mA. The lamp has 20 h life.

### Features and Benefits

- Olive shape B3 - 11 mm glass
- Alternative to vacuum types
- P13.5s prefocus base




**Specifications:**

Current Rating	500 mA
Diameter	11.3 mm
Lamp Base	P13.5s
Lamp Size	B3 1/2
Length	29 mm
Lens Colour	Clear
Life Hours	20 h
Luminosity	26 lm
Voltage Rating	4.8 V

RS Stock No.	105174
--------------	--------

*DRAWING - I*

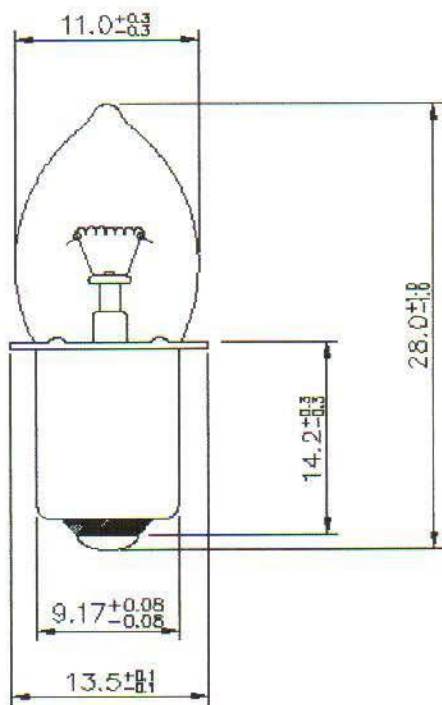

Unit : mm

1. Structure	Bulb Type	B3 1/2
	Bulb Diameter	Ø 11.3Max.
	Length	29.0Max
	Base Type	P13.5s
2. Design Characteristics	Voltage	4.8V
	Amperage	500mA± 10%
	Luminous Flux	26Lm±20%
	Life Hours	20Hrs