

Features

- Weather proof:
IP67
- Temperature
Range: -
25°C~85°C
- Cable Entry:
M20x1.5
- Terminal Stripe:
8~14
- Position Indicator:
0~90° Open-
Yellow Close-
Red

RS PRO Limit Switch Box 0834637:2DPDT

RS Stock No.: 0834637



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.


Product Description

ALS Series position monitoring switchbox a rotary position indication device and is designed to integrate with valve or NAMUR rotary pneumatic actuator with a variety of mounting options, internal switches, sensors and configurations.

General Specifications

Weather Proof	IP67 / NEMA 4,4X
Temperature Range	-25°C~85°C
Cable Entry	M20x1.5
Terminal Stripe	8~14
Position indicator	0~90° Open-Yellow Close-Red
(Mech.Switches)Type	5A/16A 125~250VAC
	M5:2DPDT
Current	5A/16A
Voltage	125~250VAC
(Proximity Sensor)Type	DC 24V (10~30VDC), ≤150mA
	PP:P&F (NAMUR)
	Exia II CT6 PA:2(wires) or 3(wires)
(Magnet Sensor)Type	5~240VAC/DC, ≤300mA
	QA:PA:2(wires) or 3(wires)

ALS-100 Classic Type

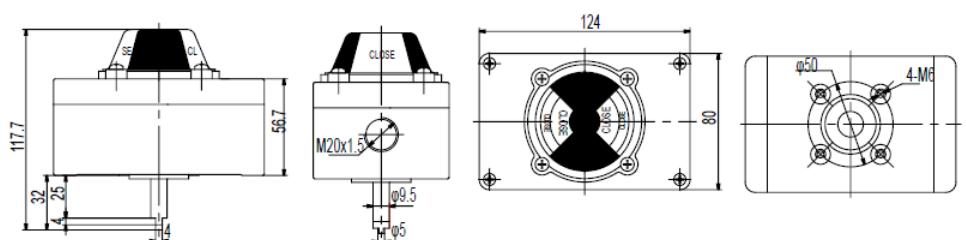

Similar Products

RS Stock No.	MPN	Weather Proof	Temperature Range	(Mech.Switches)Type
	0834636	IP67 / NEMA 4,4X	-25°C~85°C	M2:2SPDT
	0834637	IP67 / NEMA 4,4X	-25°C~85°C	M5:2DPDT

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories