




PRODUCT DATASHEET

Datasheet creation date: 2025/07/08 2:22 (UTC)



6207ZZ

Single-Row Deep Groove Ball Bearings

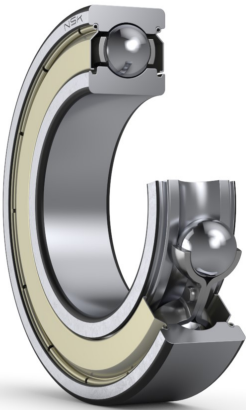

Boundary Dimensions

d	35	mm	Bore diameter
D	72	mm	Outside diameter
B	17	mm	Width
r (min.)	1.1	mm	Chamfer dimension

Basic Load Ratings

Cr	28200	N	Basic dynamic load rating
C0r	15300	N	Basic static load rating

Speeds

Grease	11000	min-1	Grease lubrication
--------	-------	-------	--------------------

Abutment and Fillet Dimensions

da (min.)	41.5	mm	Diameter of shaft abutment
da (max.)	44.5	mm	Diameter of shaft abutment
Da (max.)	65.5	mm	Diameter of housing abutment
ra (max.)	1	mm	Radius of shaft or housing fillet

Calculation factors

fo	13.8		Factor
----	------	--	--------

Additional information

z	9		Number of Balls
Dw	11.112	mm	Ball Diameter

Mass

Mass approx.	0.284	kg	Mass approx.
--------------	-------	----	--------------

