



Brand of NTN corporation


Technical data

BB10UU

Standard ball bushings closed



VISUAL (S)

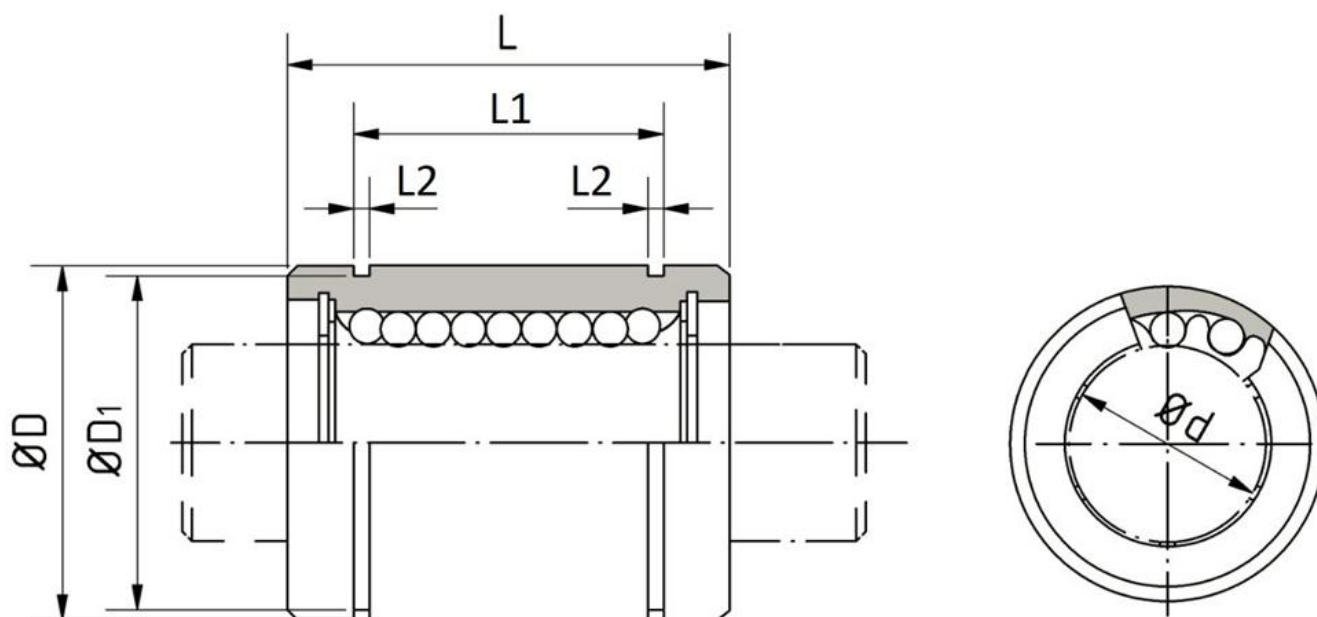

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	JIS dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	10 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

BB10UU

Standard ball bushings closed

PRODUCT DEFINITION

d - Internal diameter tolerance	0/-0,009
D - External diameter	19 mm
D - External diameter tolerance	0/-0,013
L - Length	29 mm
L - Length tolerance	0/-0,2
L1	22 mm
L1 tolerance	0/-0,2
D1 - Diameter	18 mm
L2	1,3 mm
Number of ball rows	4
Mass	0,036 kg

PRODUCT PERFORMANCE

Cmin	0,286 kN
Cmax	0,404 kN
C0min	0,594 kN
C0max	0,84 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY

Reference	BB10UU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

