

SPEEDYLOCK Locking Category 6A RJ45 Plug



SPEEDYLOCK Locking Category 6A Shielded RJ45 Plug (PGSPDY2LP)

Our ***SPEEDY***LOCK Category 6A shielded locking plug is perfect for assemblies which are secure against unauthorised or inadvertent disconnection of critical network connections. A high-performance termination is achieved quickly and with minimum effort due to use of a

SPEEDY RJ45 feedthrough plug

Features

- Perfect solution for rapid termination
- Tamper Resistant – Secure lock locks in the plug for added physical security
- Compliant with Category 6A patch cord standard.
- Should be terminated with crimp tool for feedthrough plugs, such as our TRCSPDY5
- Each plug allows twisted pair wires to be inserted through the body and pulled out of the front to ensure the correct wiring order before crimping
- By pulling the cores into the plug, twists can easily be maintained up to the contacts, enabling fully rated category performance
- Able to accommodate Category 6A with overall cable O.D. up to 6.6mm (due to limit of the SR boot)
- Suitable for inner cores up to 1.2mm O.D.
- Extended hood prevents latch snagging

NOTE: Removal tool (code: TPS) required to release lock

Specifications

- Weight: 4g (including primary packaging)
- Colour: Transparent with red secure lock
- Dimensions: 60x30x10mm (in primary packaging)
- Materials:
 - Housing: Polycarbonate UL94V-0
 - Shielding: Stainless steel
 - Colour: Transparent with red locking latch
 - Contact pin: 50"μ/1.27 μm gold plating over nickel over phosphor bronze
 - Boot: Crystal polycarbonate
- Operating temperature: -10 – 60°C

Packaging:

PGSPDY2LP: Packed in individual poly bags then in bags of 10

PGSPDY2LP#10: Packed in bags of 10 then in bags of 100


EAN number:

PGSPDY2LP: 5055386514301

PGSPDY2LP#10: 5055386514370

Commodity Code: 85444920

Country of Origin: China

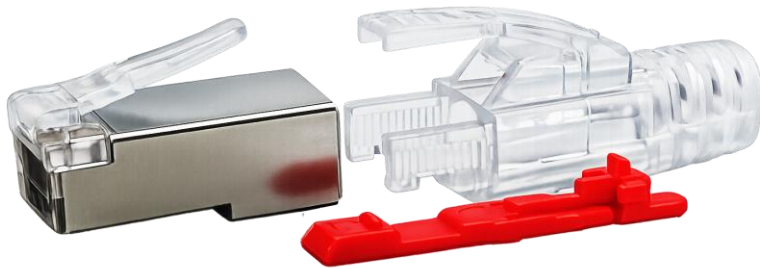

PGSPDY2LP components



Removal tool (TPS)

ROHS Compliant

Code: PGSPDY2LP

