

Datasheet

80dB PCB Buzzer

RS Stock number [511-7620](#)




Specifications:

Rated Voltage:	12VDC
Operating Voltage	3-16VDC
Rated Current:*	≤7mA
Sound Output at 30cm:*	≥80dB
Resonant Frequency:	4000±500Hz
Tone:	Continuous
Operating Temperature:	-20°C to +70°C
Storage Temperature:	-30°C to +80°C
Weight:	1g
Colour:	Black
Circuit:	Built in Oscillating Circuit
Housing Material:	Noryl
Mounting Type:	Through Hole
Base:	Sealed Base
Drive Type:	Internal

*Value applying at rated voltage (DC)

Dimensions:

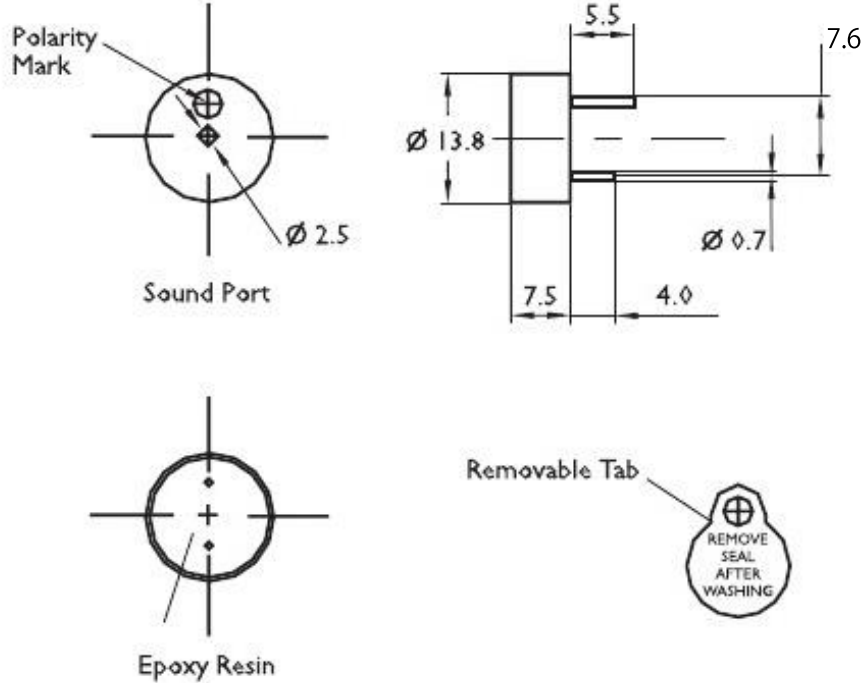

Dimensions Unit: mm
Tolerance: ±0.5mm