
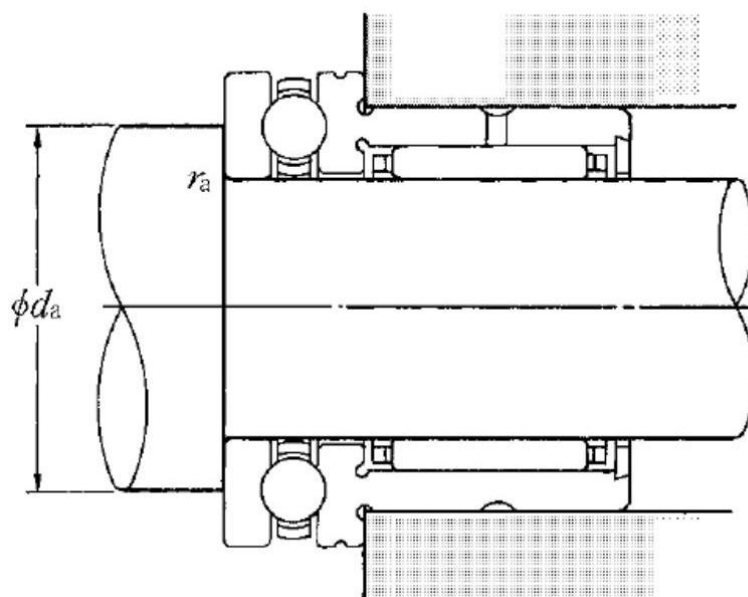


VISUAL (S)

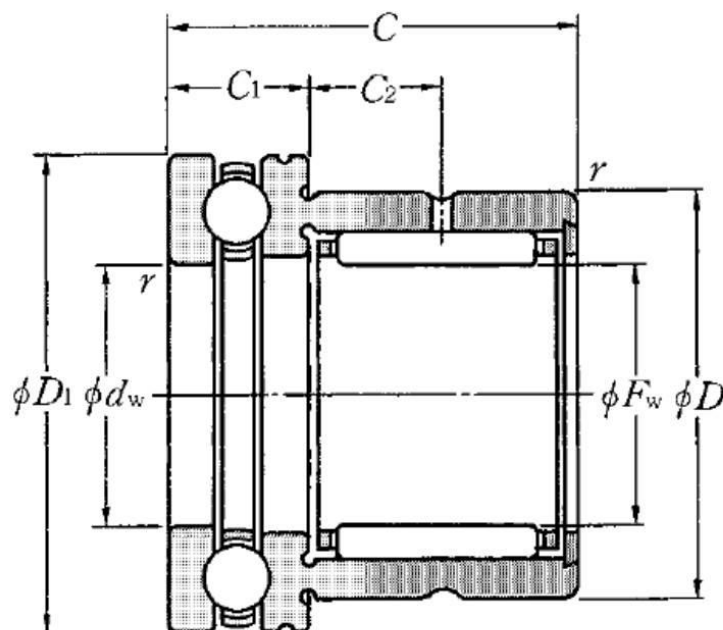

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	60 mm
dw - Shaft washer bore diameter	60 mm
D - External diameter	72 mm
D1 - Outer diameter of washer	85 mm
C - Width of bearing, drawn cup or outer ring	40 mm
C1 - Thrust bearing height	17 mm
C2 - Hole location	12 mm
rs - Min fillet radius	1 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	3 mm
Precision class	P0
Mass	0,465 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	29800000 mN
Ca - Dynamic axial load rating	41500000 mN
C0r - Static load rating	71500000 mN
C0a - Static axial load rating	113000000 mN
N lim - Grease lubrication limit speed	15600 °/s
N lim - Oil lubrication limit speed	22200 °/s
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	393,15 °K



ABUTMENT	
da min - Min shoulder diameter IR	75 mm
ras max - Max shaft & housing fillet radius	1 mm

