

# Warrior Wash-Down Scales



WSK model



Warrior scales meet the demands of tough wash-down and cleanroom environments. Solid grade 304 stainless steel construction of the base and indicator provide rugged durability. IP66-rated, the Warrior comes with all the features necessary to perform a variety of functions in the food, pharmaceutical, veterinary and manufacturing industries.

The check-weighing function, with coloured LED lights, makes smooth work of precisely weighing repetitive samples. Other application modes available on all Warrior models are parts counting, percentage weighing and dynamic weighing. The large vivid display is backlit for easy reading, reducing the chance of errors when transcribing data. With data output via a RS-232 connector and optional relay triggers, the Warrior can be set to control other devices. It is loaded with smart features you rely on Adam to deliver.

With more than 40 years of experience in the production of weighing instruments, you can trust Adam for quality products that offer a range of features designed for a variety of applications.



**ADAM**<sup>®</sup>  
**THE RIGHT BALANCE**  
Speed, Performance, Value

## Warrior Highlights:

With its IP66-rated stainless steel indicator and IP67-rated load cell, cleaning is quick and easy with a simple hosing.

LED indicators streamline check-weighing activities. Indicators for high, low and OK show the user what to do, making for faster, more accurate check-weighing procedures.

The efficiently designed keypad with colour-coded keys and symbols facilitates quick recognition of the most frequently used functions. Push-button keys are large and well-positioned, minimising the chance of errors.

Its adjustable indicator can be set to any angle, and the indicator can be rotated 360 degrees. A large backlit display and capacity tracker monitor weight limits to help protect from overloads.

The Warrior offers six weighing units and six weighing modes, including dynamic weighing for measuring moving objects such as liquids or animals, parts counting to perform inventory checks, percentage weighing, check counting and check weighing.


## Rugged wash-down design and numerous features combine in an elegant yet robust weighing scale

### Features

- Six weighing units (g, kg, lb, oz, lb:oz, N)
- Colour-coded keypad with symbols and text
- Display/hold function
- Large backlit display with capacity tracker
- Adjustable indicator for ultimate viewing angle
- Non-slip rubber feet
- Grade 304 stainless steel construction
- IP66-rated indicator and IP67-rated load cell for wash-down and dust protection
- Check-weighing LED indicators
- External automatic calibration
- RS-232 data output for connection to computers and printers
- Optional expansion unit for relay output
- Rechargeable battery with up to 90 hours of operation on a single charge
- Adjustable auto-sleep/power-down setting to save battery life

### Applications

- Weighing
- Parts-counting
- Check-weighing
- Animal/dynamic weighing
- Percentage-weighing
- Check-counting

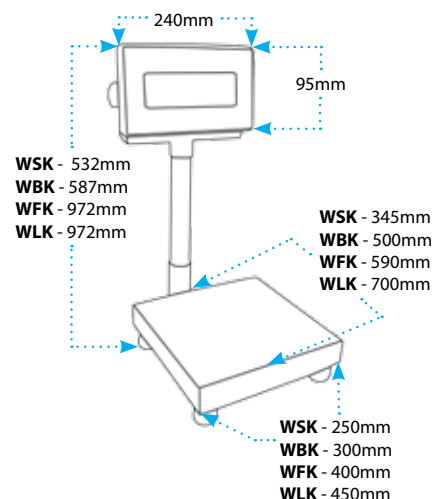

## Technical Specifications

Model	WSK 8	WSK 16	WSK 32	WBK 32	WBK 75	WFK 75	WFK 150	WLK 150
Capacity	8kg	16kg	32kg	32kg	75kg	75kg	150kg	150kg
Readability	0.5g	1g	2g	2g	5g	5g	10g	10g
Repeatability (S.D.)	1g	2g	4g	4g	10g	10g	20g	20g
Linearity (+/-)	1g	2g	4g	4g	10g	10g	20g	20g
Pan Size	250 x 250mm			300 x 400mm		400 x 500mm		450 x 600mm
Weighing Units	g, kg, lb, oz, lb:oz, N							
Stabilization Time	2-3 seconds							
Calibration	External							
Display	Backlit display with 40mm digits and capacity tracker							
Power Supply	12VDC 800mA adapter / internal rechargeable battery (both included)							
Operating Temperature	-10° to +40°C							
Housing	Type 304 stainless steel base and indicator, IP66-rated							
Overall Dimensions (wxdxh)	250 x 345 x 532mm			300 x 500 x 587mm		400 x 590 x 972mm		450 x 700 x 972mm
Net Weight	6kg			9kg		13kg		19kg

### Accessories

No. 1120011156 ATP printer  
 No. 3123011281 ATP thermal paper (10 pack)  
 No. 700000012 Adam printer

No. 400005055 Adam printer thermal paper (5 pack)  
 No. 600002028 AdamDU - data collection program  
 No. 1100011297 External relay output box