

Rubber plug

Swiss standard

SEV12S0


General information

Item number	SEV12S0
Model	Rubber plug
Colour	black

Electrical parameters

Amperage	10A
Voltage	250V
Poles	2P + PE

Standards/Directives

According to	SEV 6534 -Typ 12
Standard	Swiss standard
Certification marks	

Operating conditions


Storage temperature	-25°C to +70°C
Operating temperature	-25°C to +40°C
Relative humidity	5 to 95%, no condensation
Degree of protection	IP 44

Materials

Contact Carrier	PA
Housing	TPE

Connecting cable

Cross section	3x0,75mm ² -3x2,5mm ²
Cable diameter, dimension a	6-12mm
Insulation strip length sheath, dimension b	33-36mm
Trim L/N, dimension c	0mm
Insulation strip length cores, dimension d	8-10mm

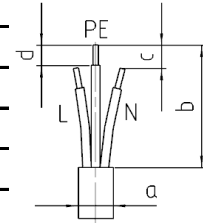


Connection screws

Max. torque for screws L-N/PE	0,5 Nm
Screw drive L-N/PE	Combined slot/PZ1
Max. torque for screws housing	1,2 Nm
Screw drive housing	Combined slot/PZ2
Max. torque for screws strain relief	0,5 Nm
Screw drive strain relief	Combined slot/PZ1

Additional technical information

Turn strain relief clamp	for wire diameter less than 8mm
--------------------------	---------------------------------

Subject to modifications

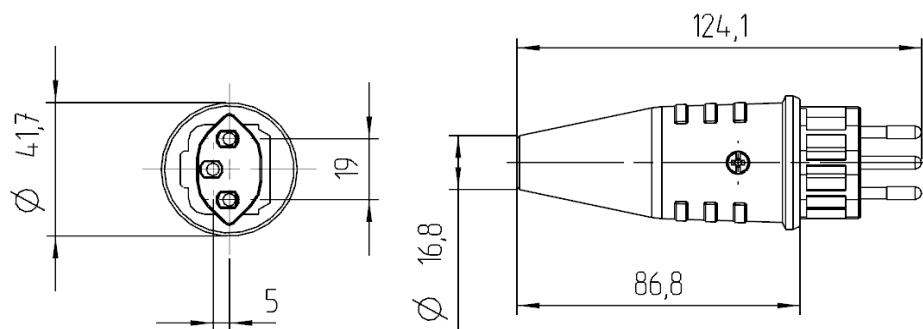

If the application requires extended specifications, we recommend to test the application under real or simulated conditions. Parameters like duration, quantity and temperature will effect the result significantly