




System Monitor Kit 1


Hydraulic Pressure Test Kit



Model: 3101-16-XX.LC

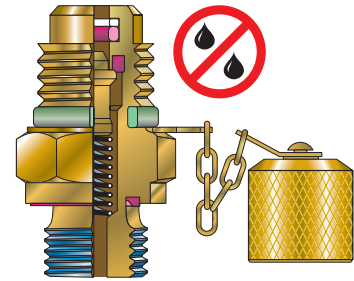

life-time leak free guarantee

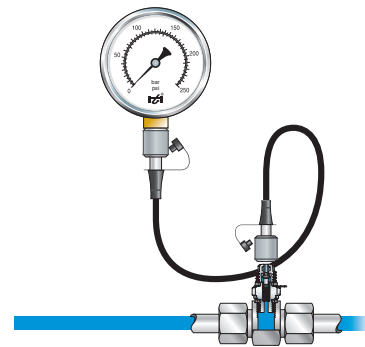

FEATURES:

- Test under pressure using leak free Minimesse™ connections up to 630 bar.
- Everything you need to get two pressure readings.
- Ultra low cost - ideal for OEM's.
- Lifetime leak free guarantee.

KIT CONTENTS

- 2 x 63mm glycerine filled pressure gauges user selectable up to 700 bar.
- 3 x Minimesse™ 1620 test points - 1/8" BSP, 1/4" BSP & M10x1 threaded.
- 1 x 630 bar rated Minimesse™ pressure test hose - 1.5 meters long.
- Additional 3/8" & 1/2" BSP male threaded adaptors & seals.

Order code:

3101-18- .50

Replace X in above code with pressure gauges required from the following options:

0 = 0 to 7 bar	5 = 0 to 100 bar
1 = 0 to 14 bar	6 = 0 to 170 bar
2 = 0 to 28 bar	7 = 0 to 280 bar
3 = 0 to 40 bar	8 = 0 to 400 bar
4 = 0 to 70 bar	9 = 0 to 700 bar

All pressure gauges have dual bar / psi scale. $\pm 1.6\%$ acc.
Special gauge ranges available on request