




Electrical performance:
CEI EN 50393
as applicable

Gel: UL 94-HB 

Halogen free:
according to CEI EN 50267 2-2

**Self-extinguishing and
resistant to abnormal
heat and fire:**

Glow wire test a +960°C
according to EN 60695-2-11

Operating temperature 

Gel operating temperature:
-60°C / +200°C 

IP69K
OFFICIALLY
TESTED

IP68
OFFICIALLY
TESTED

IMQ

Ready Box IP68

3 or 4 entrances junction boxes pre-filled with gel, complete with integrated terminal block and cable glands for 6 to 18 mm diameter cables and for 16/20/32 mm ducts/conduit.

- Ready to use, they can be installed in all environmental conditions
- Also suitable for wet or flooded environments
- Always re-enterable
- Pre-filled with gel. Non-toxic and non-classified as hazardous under CLP
- Pre-threaded entries for cable gland mounting
- Snap shut closure, does not require screws
- Wall or external ceiling fixing system
- Halogen free & UV resistant
- No shelf life


Box pre-filled with non-toxic, safe gel. Nothing to pour, mix or cast!




Ready, safe, quick and innovative



Ready Box IP68 - 120

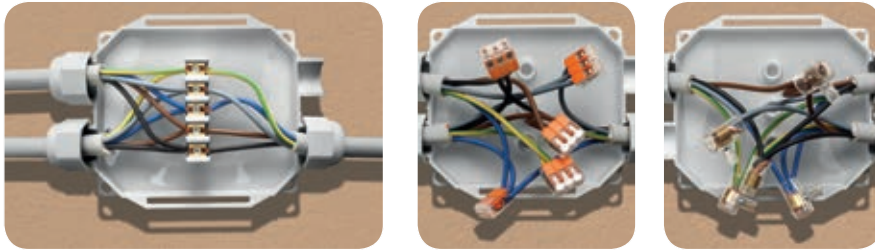

Ready Box IP68 - 90

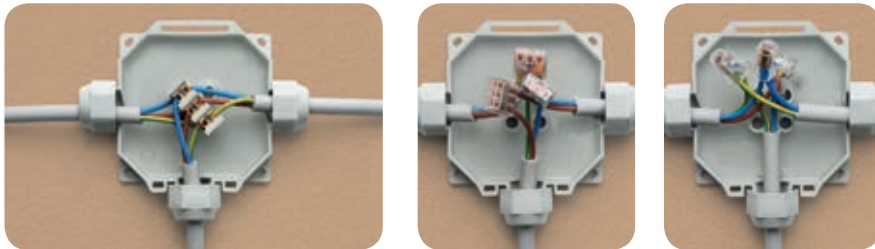

Thanks to its innovative design, unlike a standard box, there is no need to break through the walls of the box to insert the cable.

Also suitable for extra-flat lever connectors.

Also suitable for screw terminals.




Installation with free cables



Installation with cable gland duct

Revolutionary!

No additional accessories are required as it is equipped with connection block and glands M25 x 1,5

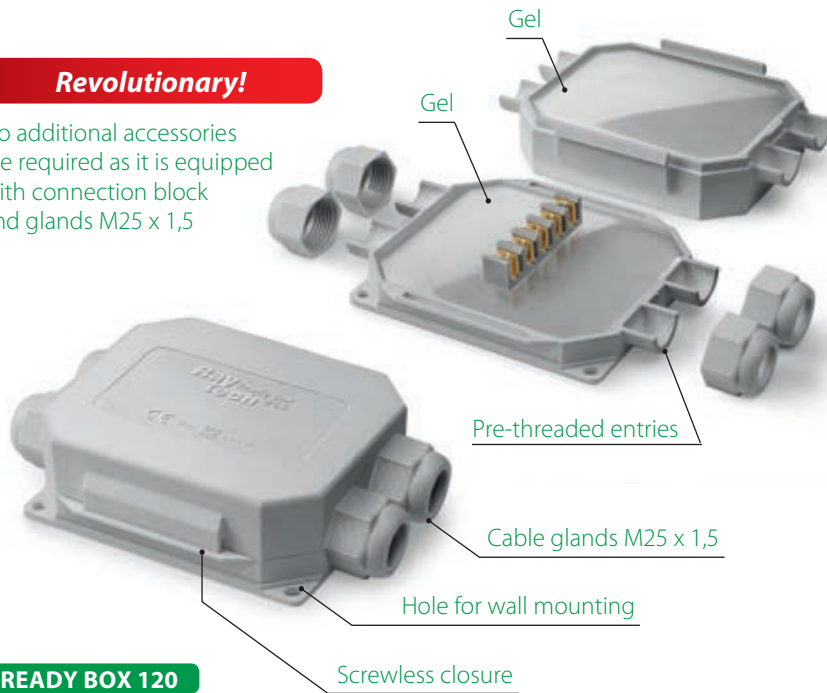

READY BOX 90

READY BOX 120

Product	Colour	Ø	Ø entrances with cable glands		Ø tubes (mm)	A x B x C (mm)
			min (mm)	max (mm)		
Ready Box IP68 90	●	3	6	18	16 / 20 / 32	90 x 90 x 45
Ready Box IP68 90/N	●					
Ready Box IP68 120	●	4	6	18	16 / 20 / 32	120 x 100 x 45
Ready Box IP68 120/N	●					

