


Item no.: 260-112
 Product description: 2-CONDUCTOR TERMINAL STRIP 12 POLE WITH FIXING FLANGE MOUNTING ADAPTER AVAILABLE FOR TS 35 (209-123) FOR SCREW OR SIMILAR MOUNTING TYPES 3.2 MM Ø

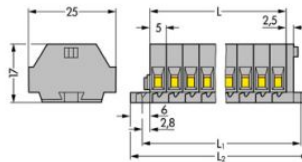

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

Product group	9 (Std Chassis Mt Blocks)
pole count	12
Cross section [mm ²]	0.08 - 1.5 mm ²
Cross section [AWG]	28 - 16 AWG
Connection method	CAGE CLAMP® CONNECTION
Number of strands	5
Measured voltage EN	400 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	18 A
Weight	20.08 g
Color	gray
Wiring type	Side-entry
No. of connection Points	24
No. of potentials	12
Height	17 mm
Height	0.669 in
Width	74.5 mm
Width	2.933 in

Depth	25 mm
Depth	0.985 in
Strip length from	8 mm
Strip length to	9 mm
Strip length	0.33 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
260-112	ABS	04-HG476174/1-PDA	400	17,5	1,5
260-112	BV	07436/C0	400	17,5	0,08-1,5
260-112	CCA	NL5800	400		1,5
260-112	CSA	18677-45	300	15	24-16
260-112	DNV	E-9215	400	18	1,5
260-112	GL	17295-00HH	400	17,5	1,5
260-112	KEMA	2110272.01	400		1,5
260-112	KR	HMB05880-EL002	400	17,5	1,5
260-112	LR	92/20242(E5)	400	17,5	1,5
260-112	PRS	TE/1718/880590/08	400		1,5
260-112	RMR	11130002	400	17,5	1,5
260-112	UR	E45172	300/300/600	10/10/5	28-16

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected