

## PREMIUM PLUS divider whiteboard 150x120cm enamel steel

- Non-foldable high-quality divider board with a double-sided whiteboard surface
- Magnetic enamel steel board surface using e3 Ceramic Steel, which is Cradle to Cradle Certified™ at the Bronze level
- Suitable for writing on with dry erase whiteboard markers
- Matte coated aluminium board frame, footings and legs in matte coated steel
- Height adjustable at two fixed positions
- Vertical and horizontal board mounting option
- Set of 4 lockable castors and flipchart hooks included
- Minimal height of the total product (vertical setup) : 196 cm
- Maximal height of the total product (vertical setup): 226 cm
- Maximal height of the total product (horizontal setup): 196 cm
- Board size: H 150 x W 120 cm


- Easily separate desks and spaces to create a safe and hygienic working environment
- Facilitates collaboration at a safe distance
- Flexibly visualise directly on the whiteboard surface or add a flipchart paper pad
- Easy to clean smooth surface
- Engineered to be bacteria resistant: the smooth, nonporous surface prevents growth and reproduction of bacteria and germs
- Attractive, lightweight and mobile design
- Tool-free mounting: quick and easy assembly
- Legs are firmly attached to the board for extra stability
- Quick linking of several boards
- 25 year guarantee on the perfect writability and wipeability of the board surface when used in combination with Legamaster accessories

### Recommended accessories

- PROFESSIONAL board accessory set 77-part Ref.:7-125500
- Whiteboard accessory holder white Ref.:7-122600
- Flipchart paper pad grid 5pcs Ref.:7-156500
- Microfibre cloth 40x40cm Ref.:7-121700
- TZ8 whiteboard cleaner 250ml Ref.:7-121300
- TZ9 whiteboard cleaner 750ml Ref.:7-121800
- TZ66 board cleaner 100pcs Ref.:7-121400

Ref.: **7-204810**

EAN: **8713797097239**

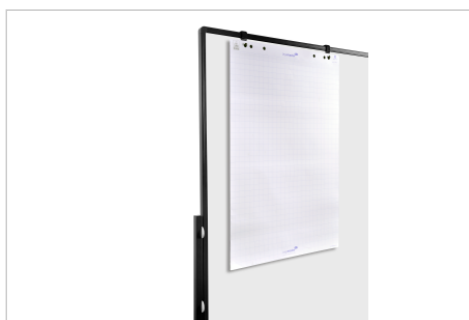



## Specifications

Surface (material/colour)	Enamel steel / white
Frame (material/colour)	Aluminium / anthracite mat
Corner (material/colour)	Plastic / -
Magnetic	Yes
Article dimensions	1250 x 1960 x 580 (mm)
Product warranty	2 years
Surface warranty	25 years

## Logistics

Quantity	1
Packing dimensions	1260 x 1577 x 89 (mm)
Weight (gross/net)	27.55 kg / 23.45 kg