


Geberit Mapress Stainless Steel adaptor union with female thread and plain end

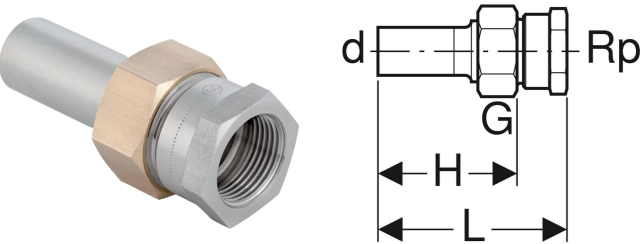

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For service water and process water
- For treated water
- For rainwater with a pH value ≥ 5.5
- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)
- For sprinklers (wet)
- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Silicone-free (LABS-free)
- Union nut made of brass
- Flat gasket made of EPDM

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	Rp "	G "	L cm	H cm
35380	12 / 15	15	1/2	3/4	8.1	5.9
35382	15	18	1/2	3/4	8.1	5.9
35384	20	22	3/4	1	8.7	6.4

Art. no.	DN	d _ø mm	R _p "	G "	L cm	H cm
35386	25	28	1	1 1/4	9.4	6.7
35387	32	35	1 1/4	1 1/2	10.1	7.2
35388	40	42	1 1/2	1 3/4	10.7	7.7
35389	50	54	2	2 3/8	12	8.4