

SCREW COVER, CONTOURED, TYPE 4



INDUSTRY STANDARDS

UL 508A Listed; Type 4, 6, 12, 13; File No. E61997
cUL Listed per CSA C22.2 No. 94; Type 4, 6, 12, 13; File No. E61997

NEMA Type 4, 6, 12, 13
CSA, File No. 42186: Type 4, 12, 13
IEC 60529, IP67

APPLICATION

With its aesthetic, rounded corners, this enclosure is an economical solution for a broad range of electrical and terminal wiring applications that do not require a back panel.

SPECIFICATIONS

- Drawn 16 gauge steel (no welded seams or sharp corners)
- Formed flanged cover
- Cover screws
- Oil-resistant gasket
- External wall-mounting brackets
- Bonding provision on cover; grounding nut in body

FINISH

ANSI 61 gray polyester powder paint inside and out







MODIFICATION AND CUSTOMIZATION

Hoffman excels at modifying and customizing products to your specifications. Contact your local Hoffman sales office or distributor for complete information.

BULLETIN: A51DR

Standard Product

Catalog Number	AxBxC in./mm	Interior Volume (in. ³)	Mounting G in./mm	Overall L x W in./mm	D in./mm	E in./mm	J in./mm	K in./mm
A402DSC	4.00 x 2.00 x 2.00 102 x 51 x 51	13.9	4.50 114	5.06 x 2.44 129 x 62	5.00 127	4.44 113	2.00 51	2.24 57
A403DSC	4.50 x 2.88 x 2.62 114 x 73 x 67	30.7	5.00 127	5.56 x 3.31 141 x 84	5.50 140	4.94 125	2.50 64	2.86 73
A404DSC	4.00 x 4.00 x 2.62 102 x 102 x 37	38.2	5.00 127	5.50 x 4.44 140 x 113	5.06 129	4.44 113	2.50 64	2.86 73

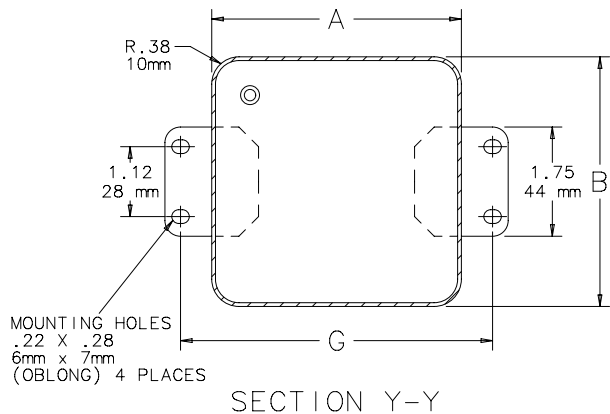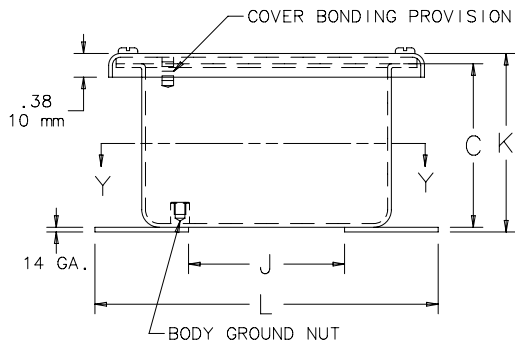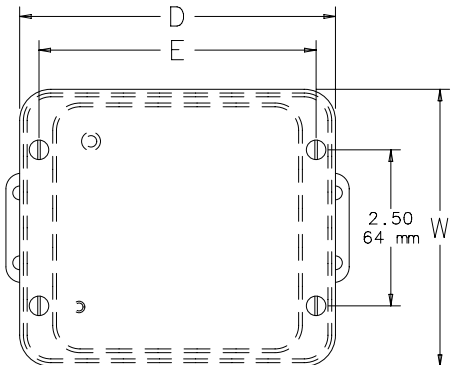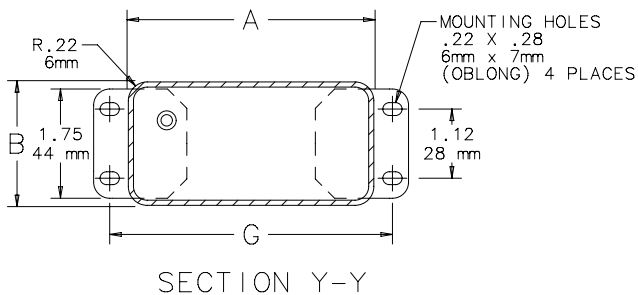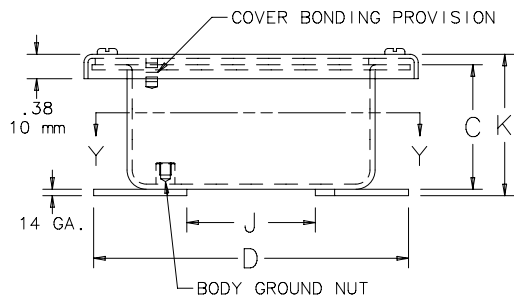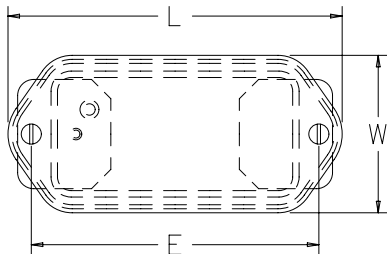

C2472-C