

Features

- 1" (DN25)
- Working Pressure: 2 ~ 20 kgf/cm²
- Working Temp: -60°C ~ 196°C
- Material: SS304
- Spring material SS 304
- Gasket material PTFE

RS PRO Safety Valves


RS Stock No.: 0336759



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- These Safety Valves are mainly suitable for boilers, pressure vessels, steam generators.
- or gas pipelines.
- The products are used for working noncorrosive fluid such as natural gas, air, and steam.
- Working Temperature: $-60^{\circ}\text{C} \sim 196^{\circ}\text{C}$
- Working Pressure: $2 \sim 10 \text{ kgf/cm}^2$ or $11 \sim 20 \text{ kgf/cm}^2$

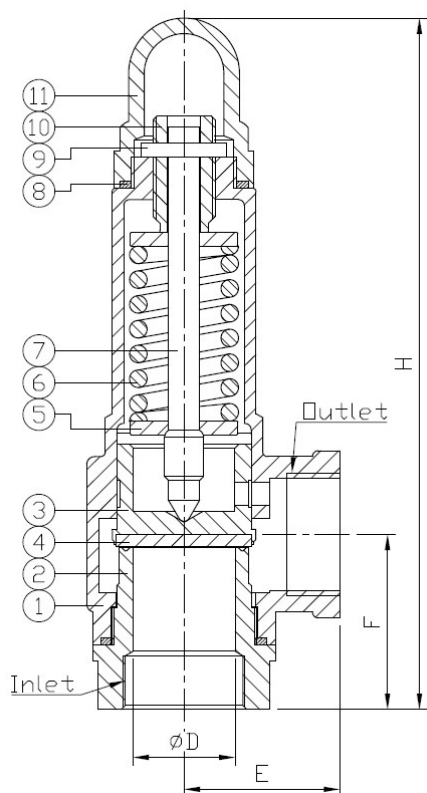

SIZE	Inlet	Outlet	D	E	F	H	Lift
1"	1"	1"	25	40	55.5	188	1

unit:mm

ITEM	PARTS	MATERIAL
1	BODY	ASTM A351-CF8
2	VALVE SEAT	SUS 304
3	DISC	
4	SEAL	PTFE
5	SPRING SEAT	SUS 304
6	SPRING	
7	STEM	PTFE
8	GASKET	
9	LOCK NUT	SUS 304
10	ADJUST SCREW	
11	CAP	ASTM A351-CF8