

Pendant control

46-458.1418

Distribution by
Rs-online



<https://www.rs-online.eao.com/component/46-45...>

Your product:



46-458.1418 Pendant control

Loading . . .

FRONT

Colour: Yellow

MOUNTING

Mounting cut-out: Ø 22 mm

Mounting type: Panel mounting

ELECTRICAL CHARACTERISTICS

Pollution degree: 3

Protection class: II, according to EN / IEC 61140

MECHANICAL CHARACTERISTICS

Tightening torque: 0.8 ... 1.2 Nm (7.1÷10.6 Lb-in)

Weight: 0.4 kg

AMBIENT CONDITION

IP front protection: IP65, IP66

IK front protection: IK07

Operating temperature: – 35 °C ... + 80 °C

CERTIFICATE

Approbations: CSA, UL

Conformities: CE

REACH: REACH compliant

RoHS: RoHS compliant

Standards: CSA C22-2, IEC EN 60204-1, IEC EN 60947-1, IEC EN 60947-5-1, UL508

OTHER

Short Description: Pendant control


Number of holes: 4

Dimension: 83 mm x 197 mm

Housing material: Plastic

Product attributes: Suitable for outdoor applications

Dimension drawings:

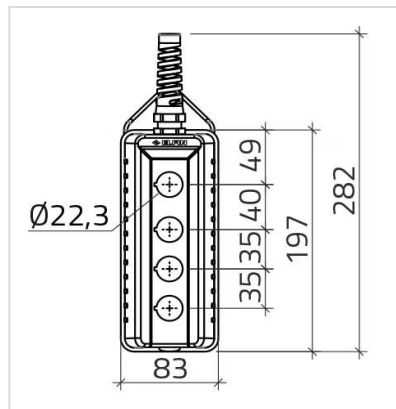

REACH:	REACH compliant
RoHS:	RoHS compliant
Standards:	CSA C22-2, IEC EN 60204-1, IEC EN 60947-1, IEC EN 60947-5-1, UL508

OTHER

Short Description: Pendant control

Number of holes: 4

Dimension: 83 mm x 197 mm

Housing material: Plastic

Product attributes: Suitable for outdoor applications

Dimension drawings:

