


# EARTHING AND NEUTRAL BUSBAR WITH GREEN/YELLOW DIN RAIL CLIP

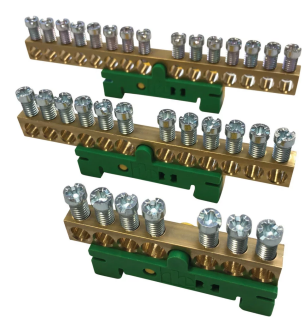

Earthing and Neutral Busbars with Green/Yellow DIN Rail Clips are used to connect multiple earthing conductors within a panel and can be used in a variety of different applications including switchgear and control equipment, electrical equipment, wind and solar power generation and in data centers.

## CERTIFICATIONS



## FEATURES

- Use to connect several earthing conductors
- Easy for the installer to add connections
- Chamfered holes allow for easy connections
- Rigid bar
- Quick and easy installation on DIN rail
- Halogen free
- RoHS compliant


## SPECIFICATIONS

**Material:** Brass;Polyethylene

Catalog Number	EB7GYSUP	EB12GYSUP	EB15GYSUP
Article Number	568678	568679	568680
Number of Connections	7	12	15
Conductor Size, IEC	(1) 6 - 25 mm <sup>2</sup> Stranded (6) 1.5 - 16 mm <sup>2</sup> Stranded	(1) 6 - 25 mm <sup>2</sup> Stranded (11) 1.5 - 16 mm <sup>2</sup> Stranded	(1) 6 - 25 mm <sup>2</sup> Stranded (14) 1.5 - 16 mm <sup>2</sup> Stranded
Max Current Rating	40A	40A	40A

Catalog Number	EB7GYSUP	EB12GYSUP	EB15GYSUP
Cross Section	124	124	124
Depth (D)	0.28	0.28	0.28
Height (H)	0.35"	0.35"	0.35"
Width (W)	2.24"	3.62"	4.45"
Hole Size 1 (HS1)	0.26"	0.26"	0.26"
Hole Size 2 (HS2)	0.22"	0.22"	0.22"
Thread Size (TS)	M5	M5	M5
Torque (TQ)	1.48 ft·lbf	1.48 ft·lbf	1.48 ft·lbf
Unit Weight	0.07 lb	0.1 lb	0.13 lb
Complies With	IEC® 60998-2-1	IEC® 60998-2-1	IEC® 60998-2-1

## DIAGRAMS

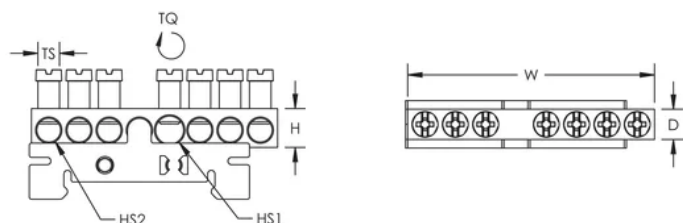

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**