

# preLink RJ45 Keystone module angled

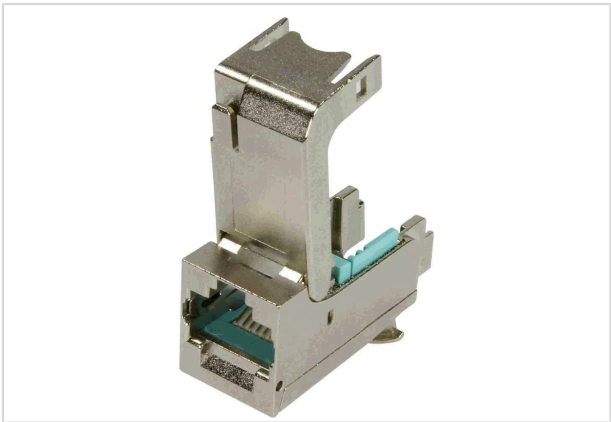


Image is for illustration purposes only. Please refer to product description.

Part number	20 82 500 0002
Specification	preLink RJ45 Keystone module angled
HARTING eCatalogue	<a href="https://harting.com/20825000002">https://harting.com/20825000002</a>

## Identification

Category	Connectors
Series	preLink®
Element	Female module
Specification	With termination block

## Version

Termination method	preLink® IDC insulation displacement termination
Size	Keystone version
Pack contents	24 pieces

## Technical characteristics

Conductor cross-section	0.1 ... 0.12 mm²
	0.22 ... 0.32 mm²
Conductor cross-section [AWG]	AWG 27 ... AWG 26
	AWG 24 ... AWG 22
Transmission characteristics	Cat. 6A Class E <sub>A</sub> up to 500 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s
Limiting temperature	-40 ... +85 °C
Degree of protection acc. to IEC 60529	IP20
Vibration resistance	5.72 m/s² acc. to IEC 61373 Category 1 Class B



Pushing Performance  
Since 1945

Technical characteristics

Shock resistance 5 g / 30 ms, 5 shocks / axis and direction acc. to IEC 61373 Category 1 Class B

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained

Specifications and approvals

Specifications	EN 45545-2
Approvals	DNV GL
PROFINET	Yes

Commercial data

Packaging size	24
Net weight	23.646 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140135741
eCl@ss	27440205 Contact insert for industrial connectors
ETIM	EC000438
UNSPSC 24.0	39121522