





RoBust LED Rope SafeGlow 25M 12W/m 1000lm/m 6500K on Reel

Article number: 147032

BAI RoBust LED Rope SafeGlow 25M 12W/m 1000lm/m 6500K On Reel Power Cable 1.8 meter with built-in 230V AC/DC adapter IP65 CLII IK10 Max. 4x interconnectable (100M)

Robust LED SafeGlow – Light and Safety Combined. The Robust LED SafeGlow is part of the trusted Robust LED Rope Plus series, meaning all compatible accessories from this line can be easily connected. It emits a strong 1000 lm/W cool white light (6500K) just like a standard Robust LED Rope, but with one major advantage: a built-in phosphor strip that glows for 10–15 minutes after power loss. An ideal emergency lighting solution to guide you safely out during a blackout. The 25-meter-long light rope comes on a convenient roll-up reel, making it easy to transport between job sites. Reliable. Durable. Safe.

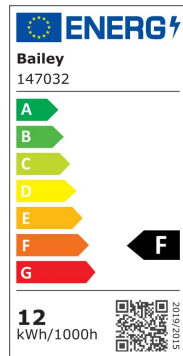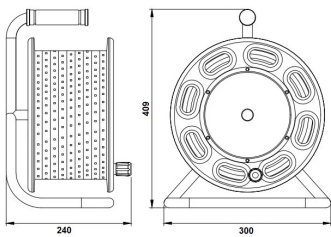

General ETIM properties

ETIM group	Luminaires
ETIM class	Light ribbon/-hose/-strip
Name	RoBust LED Rope SafeGlow 25M 12W/m 1000lm/m 6500K on Reel
Brand	Bailey
Productseries	RoBust LED rope plus
Producttype	12W/m SafeGlow

ETIM specifications


Total length [m]	25
Luminous flux per meter [lm]	1000
Colour temperature [K]	6500 - 6500
Colour of light	White
Lamp voltage [V]	220 - 240
Degree of protection (IP)	IP65
Model	Hose
Mounting method	Other
Lamp type	LED not exchangeable
Number of nodes per meter	180
Lamp power per meter [W]	12
Voltage type	AC
Beam angle [°]	120
Type of control gear	LED operating device voltage-controlled
Suitable for dimmer	Yes
Exchangeable control gear	Yes
Rated lifetime L70/B50 at 25 °C [h]	30000
Lumen maintenance at median useful life of 50,000 h at 25 °C ambient (tq) [%]	70
Failure rate at median useful life of 50,000 h at 25 °C ambient (tq) [%]	50
Max. system power [W]	300
Constant light output (CLO)	Yes
Colour rendering index CRI	80-89
Power factor	0.9
Colour of light adjustable	No
Luminous flux adjustable	No
Beam angle adjustable	No
Width [mm]	16
Height/depth [mm]	8
Lowest bending radius [mm]	68
Luminaire efficacy [lm/W]	83
Length of particular segments [mm]	1000
With end piece	Yes
With connection set	Yes
With protective cover	Yes
Self-adhesive	No
Type of wiring	Loop-through wiring included
Number of poles	2
Conductor cross section [mm²]	1.5
Connection type	Other
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No

Compatible with Amazon Alexa	No
IFTTT support available	No
Energy efficiency class of the light source according to EU regulation 2019/2015	F
Type of power supply	Battery

Complementary articles



146928
Mounting Hook Yellow for LED Rope

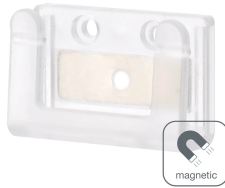

146927
Mounting clip with Magnet for LED Rope