


Part no. : 7603

Receptacle


switched, with mechanical DUO-interlock; can be padlocked

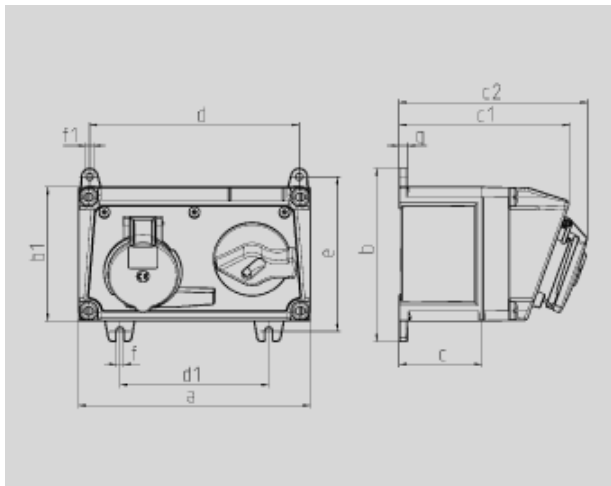

Drawing 1 MB 550 Dim. in mm	Amp. Poles	16			32		
		3	4	5	3	4	5
a		225	225	225	225	225	225
b		168	168	168	168	168	168
b1		130	130	130	130	130	130
c		80	80	80	80	80	80
c1		166	166	166	166	166	166
c2		182	183	183	193	193	193
d		204	204	204	204	204	204
d1		145	145	145	145	145	145
e		150	150	150	150	150	150
f		7	7	7	7	7	7
f1		Ø7	Ø7	Ø7	Ø7	Ø7	Ø7
g		8	8	8	8	8	8

 Article-group : **1100**

voltages : 230V

rated current : 16A







pole : 3 pole

IP protection types : 44

position of ground contact : 6h

weight : 1296

PART NUMBERS

	V	110V	230V	400V	500V	>50-500V	
	Hz	50,60	50,60	50,60	50,60	100-300	300-500
	colour						
	amp.						
16 A	3	7602	7603				
	4		7604	7605	7606		
	5			7607			
32 A	3	7611	7612				
	4		7613	7614	7615		
	5			7616			