


DATASHEET



BTEVPEM

**BT EVO 230V IP65 IK10 Adjustable Wattage and CCT
Emergency LED Bulkhead with a Daylight Sensor**

www.mlaccessories.co.uk

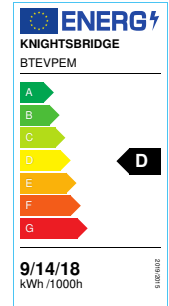

MLA PART CODE	BTEVPEM
DESCRIPTION	BT EVO 230V IP65 IK10 Adjustable Wattage and CCT Emergency LED Bulkhead with a Daylight Sensor
NET WEIGHT (KG)	0.93
FINISH	White
DIFFUSER	Opal
DIMENSIONS (MM)	Diameter - 300 Projection - 65
CONSTRUCTION	Construction - Polycarbonate
CLASS	II
IP RATING	IP65
IK RATING	IK10
WATTAGE (W)	9/14/18
LAMP TECHNOLOGY	SMD LED
LUMENS (LM)	890/930/915,1295/1400/1330,1520/1750/1585
LUMENS LIGHT SOURCE ONLY (LM)	1215/1900/2300
LUMEN TOLERANCE	5%
EFFICACY (LM/W)	136/136/134
LUMENS EMERGENCY MODE (LM)	120
CIRCUIT WATTAGE (W)	8.9/13.6/16.8
CCT	3000/4000/5700K
LIGHT COLOUR	CCT
CRI	>85
SDCM	<6
RUNNING CURRENT (A)	0.044/0.062/0.076
DISPLACEMENT FACTOR	>0.7
SVM	0.05
PST-LM	0.15
BEAM ANGLE (DEGREES)	120
L70B50 LIFESPAN (HRS)	50,000

DIMMABLE	No
EMERGENCY	Maintained / Non-maintained (not Switched)
DIFFUSER RATING	TP(b)
OPERATING TEMPERATURE	-20~35°C
INPUT VOLTAGE	230V 50Hz
DRIVER	DRIVER TYPE - Constant Current MAX. OUTPUT - 16.2W OUTPUT CURRENT - 360mA POWER FACTOR - 0.97 EFFICIENCY FULL LOAD - 0.87 ISOLATION - SELV AMBIENT TEMPERATURE (Ta) - -20~50°C CASE TEMPERATURE (Tc) - 85°C
SENSOR TYPE	Photocell
SENSOR OVERRIDE	No
BATTERY TYPE	LiFePO4
BATTERY INCLUDED	Yes
STANDBY POWER	0.5W
WARRANTY	5year(s)
MANUFACTURED IN ACCORDANCE WITH	BS EN 60598
ORIGIN OF MANUFACTURE	China
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes
EAN	5056270852455

Date Created: 03/06/2025 13:29

