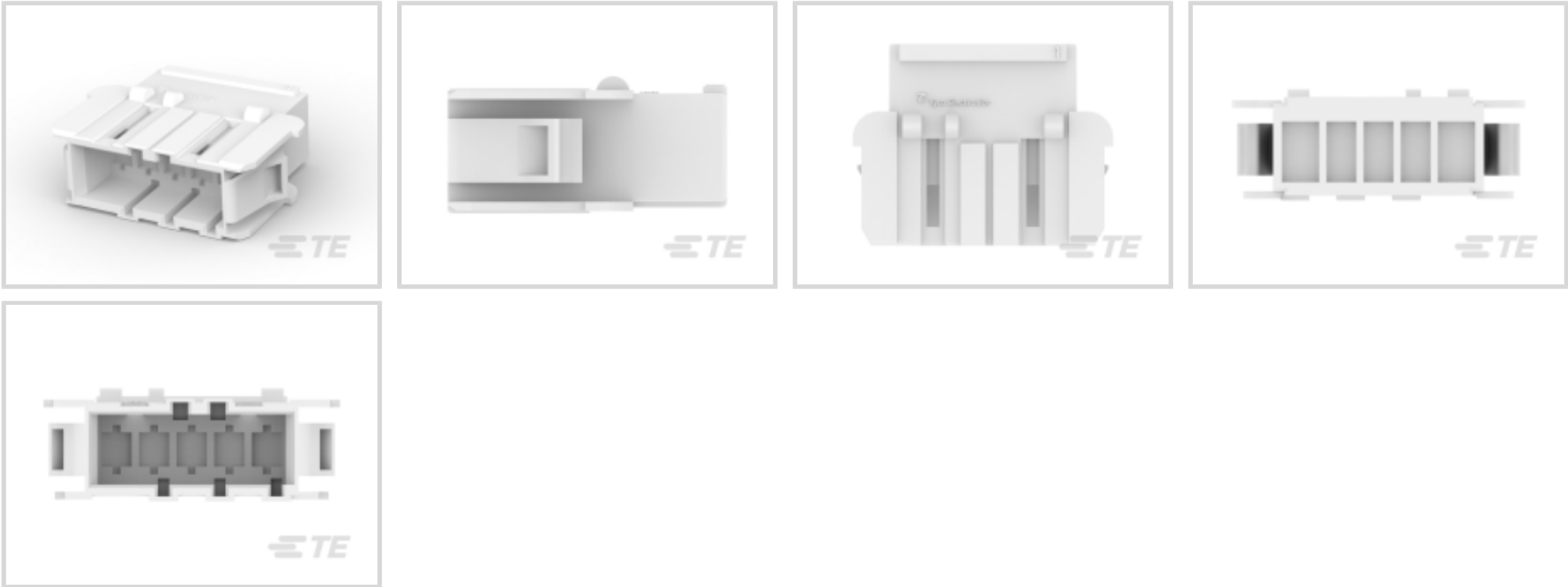




Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings



Terminal Type: **Tab**
Connector & Housing Type: **Tab Housing**
Number of Positions: **5**
Terminal Orientation: **Straight**
UL Flammability Rating: **UL 94V-2**

Features

Product Type Features

Sealable	No
Connector & Housing Type	Tab Housing

Configuration Features

Number of Positions	5
---------------------	---

Body Features

Connector & Keying Code	C
Primary Product Color	Natural

Contact Features

Terminal Type	Tab
Terminal Orientation	Straight
Contact Mating Retention	With

Mechanical Attachment

Mating Alignment Type	Polarization
-----------------------	--------------



Mating Retention Type	Locking Lance
Mating Alignment	With
Connector Mounting Type	Panel Mount

Housing Features

Housing Material	Polyamide
Centerline (Pitch)	5 mm[.196 in]

Dimensions

Product Length	30.5 mm[1.2 in]
----------------	-----------------

Usage Conditions

Operating Temperature Range	-25 – 105 °C[-13 – 221 °F]
-----------------------------	----------------------------

Industry Standards

UL Flammability Rating	UL 94V-2
------------------------	----------

Packaging Features

Packaging Quantity	200
--------------------	-----

Product Compliance

For compliance documentation, visit the product page on [TE.com](#)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

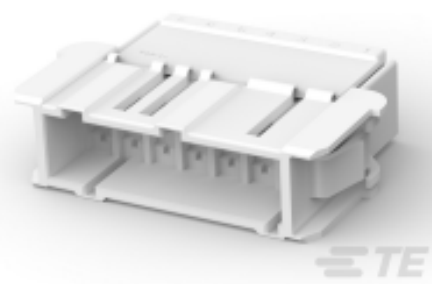
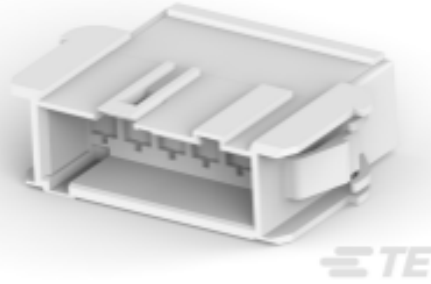
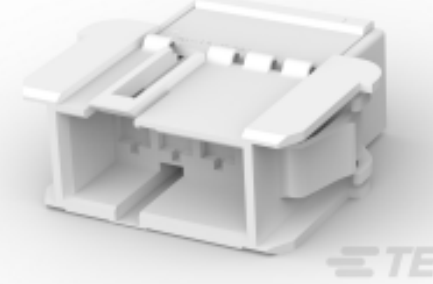
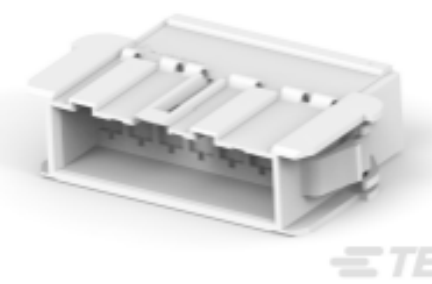
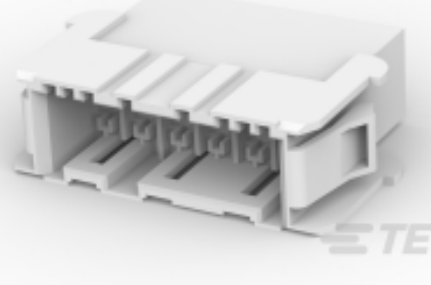
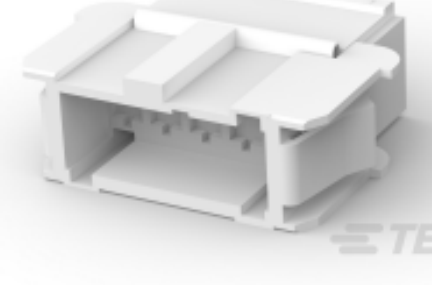
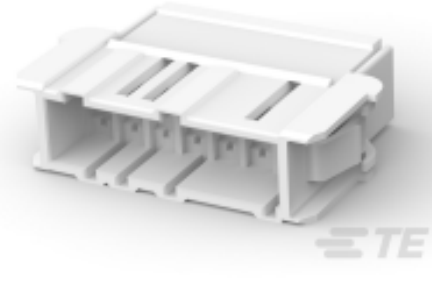
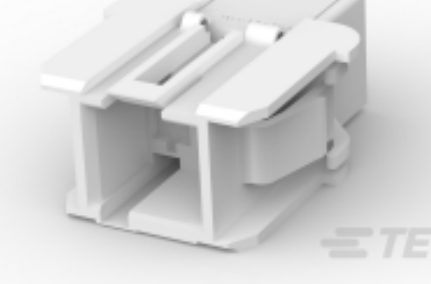
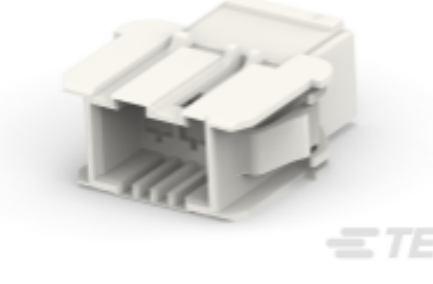
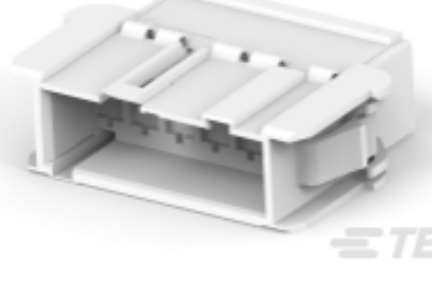
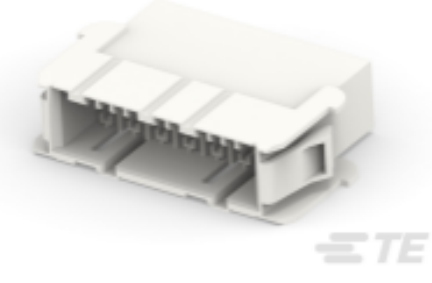
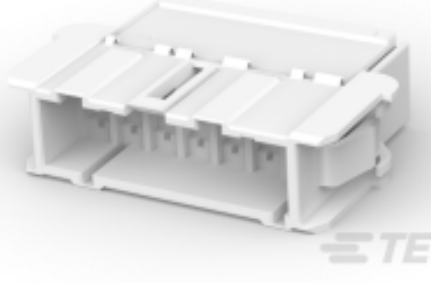
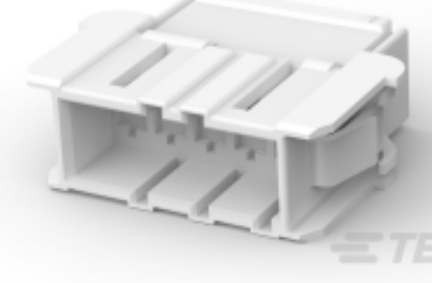
Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits



as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 293034-1 7 POSITION FASTIN FASTON TAB HOUSING (PA)	 TE Part # 1-927742-6 6 POS. FASTIN-FASTON* TAB HSG RAST5	 TE Part # 9-927742-4 4POS FASTIN FASTON HOUSING	 TE Part # 927742-7 7P FF FLACHSTGH6,3
 TE Part # 1241969-8 FASTIN FASTON HOUSING 8P	 TE Part # 5-1241967-6 6POS. FASTIN-FASTON* TAB HSG, RAST5	 TE Part # 5-1241969-8 FASTIN FASTON HOUSING 8P	 TE Part # 5-964492-5 FASTIN FASTON HOUSING 5POS
 TE Part # 293267-1 7 POS. FASTIN-FASTON+ TAB HOUSING RAST 5	 TE Part # 9-927742-2 2POS FASTIN FASTON HOUSING	 TE Part # 928230-3 3 POS FASTIN/ON HOUSING PANEL MOUNT	 TE Part # 5-927742-6 6 POS FASTIN/ON HOUSING PANEL MOUNT
 TE Part # 5-1241967-7 7POS. FASTIN-FASTON* TAB HSG, RAST5	 TE Part # 284985-1 7 POS. FASTIN-FASTON CONN. TAB HSG, RAST	 TE Part # 5-927742-3 3P FF FLACHSTGH6,3	 TE Part # 293010-1 5 POS. FASTIN-FASTON CONN. TAB HOUSING R



TE Part # 9-1241857-5
5POS. FASTIN-FASTON* TAB HSG,
RAST5

TE Part # 927742-4
4 POS FASTIN/ON HOUSING PANEL
MOUNT

TE Part # 928309-7
7P FF FLACHST GEH

TE Part # 927742-6
6 POS FASTIN/ON HOUSING PANEL
MOUNT

Also in the Series | RAST 5 IDC Connectors

Connector Contacts(12)

Crimp Terminal Housings(39)

Insertion & Extraction Tools(1)

PCB Headers & Receptacles(417)

Power Contacts(3)

Rectangular Power Connectors(481)

Standard Edge Connectors(31)

Wire-to-Board Headers & Receptacles
(417)

Customers Also Bought

TE Part #42037-1
RING TERMINAL 22-18 AWG TPBR

TE Part #1394430-3
MAG MATE CONT. 5D

TE Part #293008-5
3 POS. FASTIN-FASTON CONN. TAB
HOUSING R

TE Part #177916-1
AMP POWER DBL LOCK TAB (S)

TE Part #62308-2
AMVAR SPLC 3000-7000 020TPBR

TE Part #1217071-1
CONTACT, BLADE 125 20-16 AWG
TPBR

TE Part #1971784-2
PTL TAB CONTACT, 16-19 AWG, 2X22
AWG

TE Part #293041-2
FF 250 TAB 0.35-1.0MM2 TPBR



Documents

Product Drawings

5 POS FASTIN/ON HOUSING PANEL MOUNT

English

CAD Files

Customer View Model

ENG_CVM_CVM_1241857-5_D.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1241857-5_D.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1241857-5_D.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

FASTIN_FASTON_Product_Line

English

RAST Connector System Catalog

English

Product Specifications

Product Specification

English

Agency Approvals

UL Report

English