


Verbatim LED PAR16 GU10 7.3W

4000K Neutral White 440 LM DIM



- GU10 Socket
- 220 - 240 V Voltage
- 35,000 hours Lifetime
- Dimmable
- 88% Energy Saving
- Equivalent to 62W incandescent bulb

Product Number	52236
General Data	
Lamp Socket	GU10
Electric Data	
Wattage (W)	7.3
Wattage Equivalent (W)	62
Voltage (V)	220 - 240 V
Dimmable	yes
Power Factor	0.9
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	56.6
Diameter (in mm)	49.9
Weight (g)	65
Photometric Data	
Luminous Flux 90° Cone (lm)	440
CRI	80
CCT (K)	4000
Luminous Intensity (cd)	830
Beam Angle (°)	36
Luminous Efficacy (lm/W)	60
Lifetime (hrs)	35,000
Switching Cycle	60,000

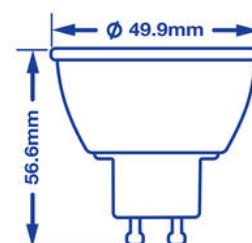


02/07/2014

Photometric Diagrams

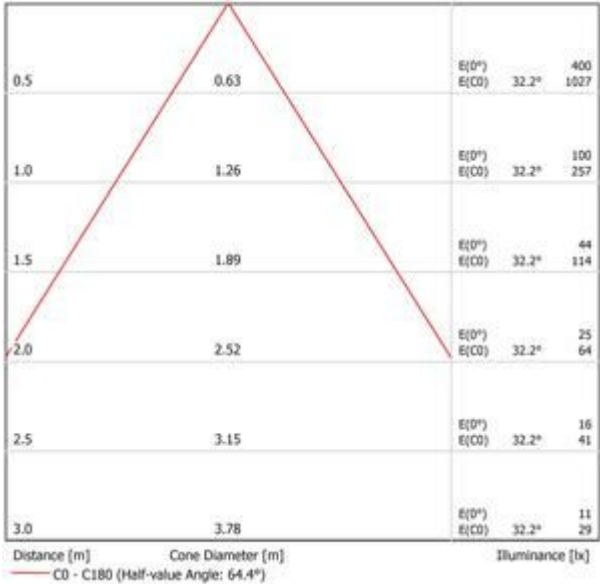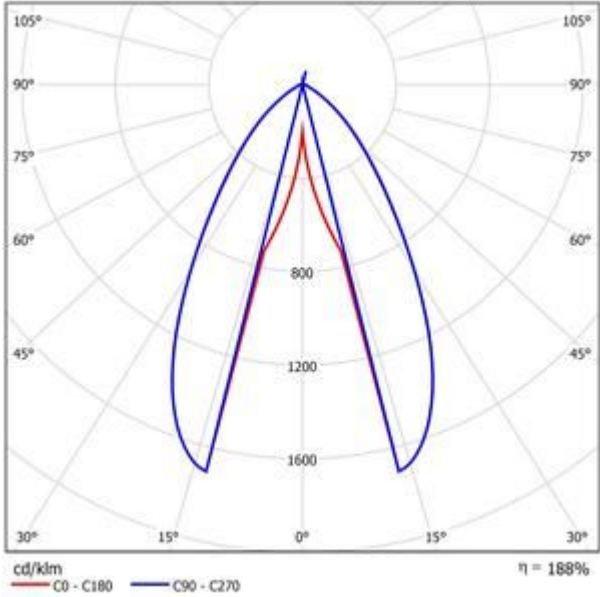

Energy Rating

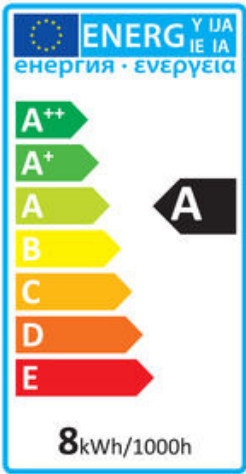

Technical Packaging Details

Barcode
023942522362
EAN 128
(02)00023942522362(37)10(91)162
EAN 14
50023942522367
Pack Dimensions(HxWxL)
H 65 x W 50 x L 50
Pack Weight
81
MOQ
10
Carton Dimensions (HxWxL)
H 58 x W 135 x L 287
Cartons/Pallet
256
Layers/Pallet
16
Units/Pallet
2560

02/07/2014