


FEATURES

- Spring-loaded
- Single-handed operation
- Moulded plastic handles

RS PRO 190mm Straight Cutters

RS Stock No.: 450-3963

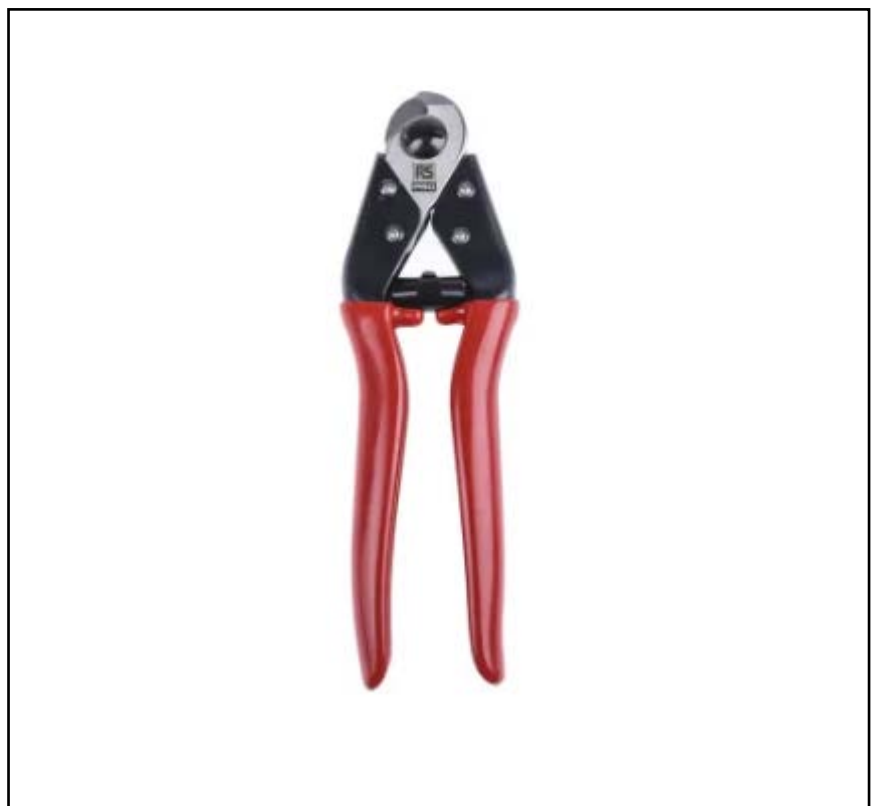

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From RS PRO, this robust cable cutter is tough enough to cut through steel wire rope. With high carbon steel blades, this wire cutter is able to cut steel wire without distorting the end profile of the material. With a special action and ergonomic handles, the wire rope cutters are easy to use and deliver an efficient cut.

General Specifications

Type	Straight Cutters
Applications	Cable, Mild Steel, High Tensile Steel Rope, Copper Wire, Aluminium Rods, Spring Steel Wire

Electrical Specifications

VDE/1000V Approved	No
---------------------------	----

Mechanical Specifications

Overall Length	190mm
Material	High carbon steel sheet (k-5) for cut blades, medium carbon steel (s1045c) screws, low carbon steel (s1008c) for rivets, lock lid and body, spring steel for high tension return spring
Hardness	Heat treated to hrc: 56-63 degree (cutting edge), hrc: 38-45 degree (screws) and rivet-hrc: 25 degree up
Finish	Fully polish cut blades, chemical black finish for screws return springs and steel frame, red vinyl coating handle
Handle Material	Red Vinyl Dipping

