

This is a sample photo.

ORDER SYMBOL: PC 281913T


EL.number **EAN:** 6418074005434

Sweden:
Denmark:
Finland: 3423805

INCLUDING:
Enclosure body, cover, 4 slotted cover screws, and mounting screws.

APPROVALS:
USA: UL Type 1, 3, 3S, 4, 4X, 12 (E75645 Vol.1 Sec.2); UL 94-V0
EURO: IP 67; UL 94-V0
OTHERS: IEC 529, CE, EEI, SETI 154171-01, CSA LR 49336-7

FIBOX SOLID PC

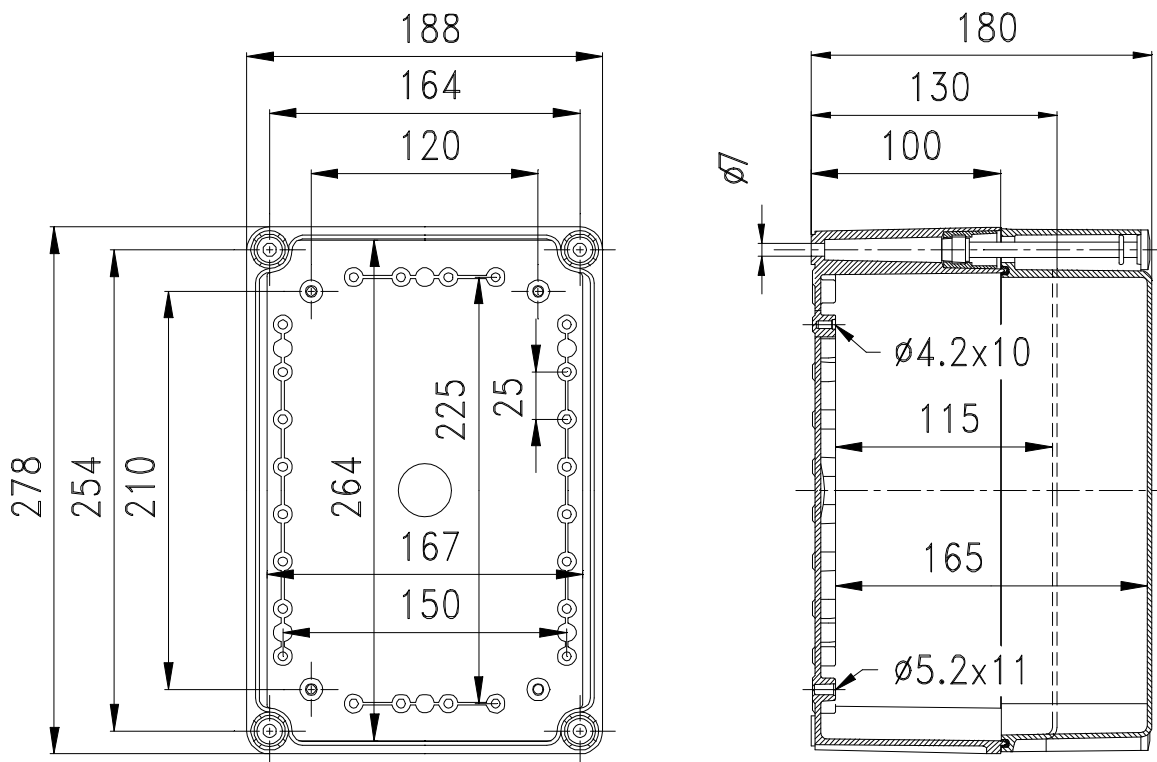

TECHNICAL INFORMATION:

Standard colour: RAL 7035	Temp.range in cont. use: Max. +80 °C
Ingress protection: IP 67 (IEC 529)	Temp. range of material: - 40 °C - + 120 °C
Flame resistance: UL 94-V2	

ACCESSORIES

Extension frame	EKJZR	DIN-Rail	EKV 24
Extension frame	EKMZR	DIN-Rail	EKV 32
Extension frame	EKOZR	DIN-Rail	EKV 34
Extension frame	EKPZR	Corner plug	MB 10523
Extension frame	EKTZR	Fastening lug	MB 10674
Extension frame	EKUZR	Earth bar support	MB 26069
DIN-Rail	EKV 12	Earth bar set	MR 26059
DIN-Rail	EKV 14		
DIN-Rail	EKV 22		