




ENGLISH

**Datasheet**

**Stock No: 815-694**

# RS Pro Standard DIN Rail Terminal, RK Series

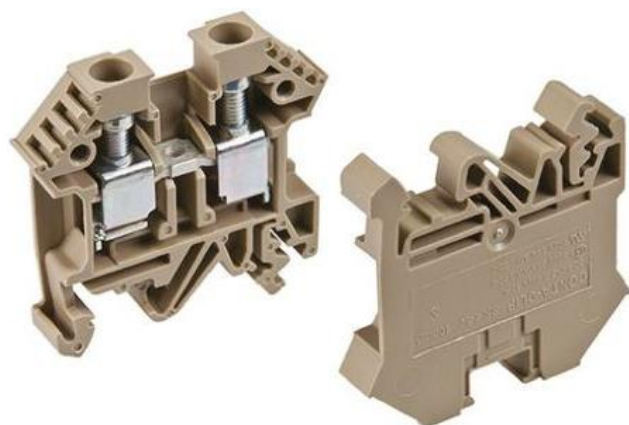

## Product Details

### Standard Feed Through

DIN rail mounted terminals, with universal mounting foot clips to both 'G' profile (asymmetric to BS5825:1990) and 'top hat' profile (symmetric to BS5584:1978) rails, with a range of features to suit all applications. The 2.5 to 10mm<sup>2</sup> terminals have common end covers and partitions, there are 10 pole Jumper Bars available for cross connection and are easily fitted with markers on either side.

### Note

Please see jumper bars for compatibility

### Approvals

UL, CSA, NEMKO, GOST

### RS DIN Rail Terminals 2

### Approvals

UL, CSA



ENGLISH

Compatibility Table			
Stock number	End cover	Pre-assy jumper bar	Markers
815-638	815-650	815-789	460-610
815-644	815-650	815-789	460-610
802-777	815-688	-	460-610
802-783	815-688	-	460-610
815-666	815-688	815-795	460-610
815-672	815-688	815-795	460-610
815-694	815-688	815-802	460-610

## Specifications:

Series	RK
Wire Size	22 → 8 AWG
Cable CSA	0.2 → 10mm <sup>2</sup>
Colour	Brown
Current Rating	65A
Termination Method	Screw Down
Voltage Rating	800 V
Minimum Operating Temperature	-40°C
Maximum Operating Temperature	+105°C