




- + Cast iron pump body
- + self-priming pump

Model: GARDENJET 1000
Part number: N4177010
Barcode: 7630014538485

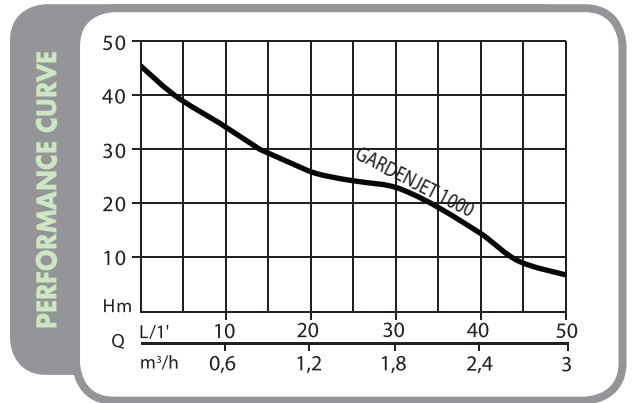


Surface Pump for Irrigation and Water Supply applications. Gardenjet 1000 is a single phase and self priming pump, with single JET impeller to assure great efficiency and easy priming

Applications

- irrigation of lawns and flowerbeds
- washing of terraces or outdoors floors
- basins or expansion tanks filling/draining

Accessories

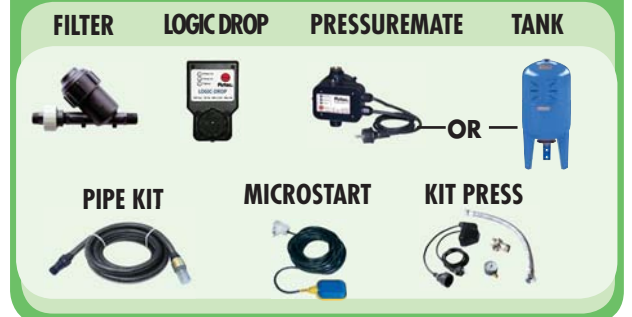

Technical data

Absorbed power	800 Watt	Pump body	Cast iron
Voltage	230 V	Power cable	1.5m
Flow rate	3.300 l/h	Suction/Delivery port.	33.25 mm (1" F)
Max. Head	46 m	Max. advised suction head	7 m
Rated current	3.3 A	Weight	8.9 Kg
N° Impellers	1	Packaging dimensions	38.5 x 19.5 x 27.5 cm
Protection class	IPX4	PCS per pallet	72

