


Type

WK 007

80 x 80 x 38 mm

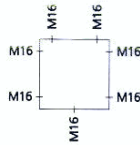

Description

IP 54 junction box, $U_i=400\text{ V}$,
Duroplastic, halogen-free
 With IP 54 adapters and M16 sealing plugs
 Seal range 6-10 mm

Order No. Packing Qty

WK 007 L – empty, grey



402 907 01 60 / 5

WK 007 – 2,5²,
 grey, 5 pole screw terminal 2,5 mm²

402 407 01 60 / 5

WK 040

87 x 87 x 45 mm

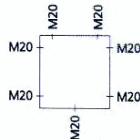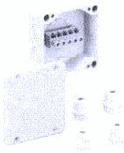

IP 54 junction box according to E DIN IEC 60998-2-5, $U_i=690\text{ V}$,
Duroplastic, halogen-free
 With IP 54 adapters and M20 sealing plugs
 Seal range 8-13,5 mm

WK 040 L – empty, grey

404 907 01 60 / 3

WK 040 – 4²,
 grey, 5 pole screw terminal 4 mm²

404 407 01 60 / 3

Recommended Accessories:


IP 68 cable gland with lock nut
 M20 (seal range 6 - 12 mm)

227 420 01 50



WK 060

100 x 100 x 50 mm

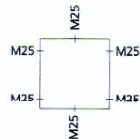

IP 54 junction box according to E DIN IEC 60998-2-5, $U_i=690\text{ V}$,
Duroplastic, halogen-free
 With IP 54 adapters and M25 sealing plugs
 Seal range 9-18,5 mm

WK 060 L – empty, grey

406 906 01 30 / 3

WK 060 – 6²,
 grey, 5 pole screw terminal 6 mm²

406 406 01 30 / 3

Recommended Accessories:


IP 68 cable gland with lock nut
 M25 (seal range 7 - 16 mm)
 Lead seal set

227 425 01 25
 450 010 01 10



WK 100

115 x 115 x 66 mm

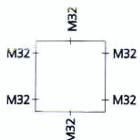

IP 54 junction box according to E DIN IEC 60998-2-5, $U_i=690\text{ V}$,
Duroplastic, halogen-free
 With IP 54 adapters and M32 sealing plugs
 Seal range 13-23 mm, with lead seal set

WK 100 L – empty, grey

410 906 01 20 / 1

WK 100 – 10²,
 grey, 5 pole screw terminal 10 mm²

410 406 01 20 / 1

Recommended Accessories:

IP 68 cable gland with lock nut
 M32 (seal range 11 - 21 mm)

227 432 01 10

