

HALODIUM II BT 400 W D

HALODIUM II | Outdoor flood- and spotlights



Areas of application

- Facades and monuments
- Parks

Product benefits

- Ready for installation

Product features

- Asymmetrical hammered reflector made of anodized aluminum
- 5 mm shield made of tempered glass with a mesh overprint
- Type of protection: IP66
- Impact resistance: IK06



Technical data

Electrical data

Operating mode	CCG
Lamp wattage	400 W
Nominal voltage	230 V
Mains frequency	50 Hz

Photometrical data

Color temperature	5200 K
Luminous flux	35000 lm
Luminaire efficiency	0.74

Light technical data

Light distribution	Symmetric
--------------------	-----------

Dimensions & weight

Length	535.0 mm
Width	437.0 mm
Height	195.0 mm

Colors & materials


Body material	Aluminum
Product color	Anthracite
Cover material	Glass

Temperatures

Ambient temperature range	-20...+35 °C
---------------------------	--------------

Additional product data

Product datasheet

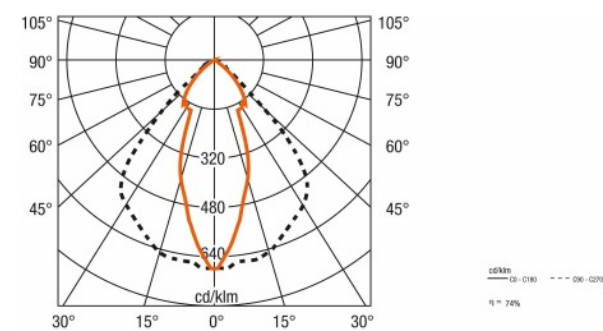

Luminous intensity distribution

Number of lighting outlets	1
Equipment	HQI-BT 400 W/D
Equipped with lamp	Yes
Reflector type	Symmetric
Type of cover	Clear glass

Capabilities

Type of installation	Surface-mounted
Adjustable	Yes
Dimmable	No
Type of connection	Terminal, 3-pole
Accessories	Protection grid (4050300104539) / Deflector grid (4050300104522) / Bracket (4008321380395) / Glass (4008321388360)

Certificates & standards

Protection class	I
Type of protection	IP66
Protection against ignition and fire	F

Country specific categorizations

Order reference	HALODIUM II AZ
-----------------	----------------

Product datasheet

Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4008321940124	OSRHL2BT400DSM	-	4516045	-

Product datasheet



Detail



Detail

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321940124	HALODIUM II BT 400 W D	Shipping carton box 1	455 mm x 230 mm x 500 mm	52.33 dm ³	12824.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.