

Fiche Technique / Data sheet

180849 - LET 1021 DW / LED GLASS TUBE – G13 T8 18W 6500°K


TECHNICAL CHARACTERISTICS	
Type	T8 LED Glass Tube
Socket	G13
Voltage (V)	230 V
Power (W)	18W
Colour Temperature (°K)	6500°K
Lumens (lm)	2000lm
Diameter (mm)	30 mm
Length (mm)	1200 mm
Dimmable	No
CRI	80
Average Life Time	40 000 HRS
Angle	280°
Power factor	0.9
IP Protection	20
Certification	ROHS/CE
Energy Class	O / Y




INSTALLATION :

1. Switch off the power
2. Take out the fluorescent lamp, then the starter
3. Replace the LED starter
4. Insert the LED tube

Installation – Magnetic Ballast Circuit

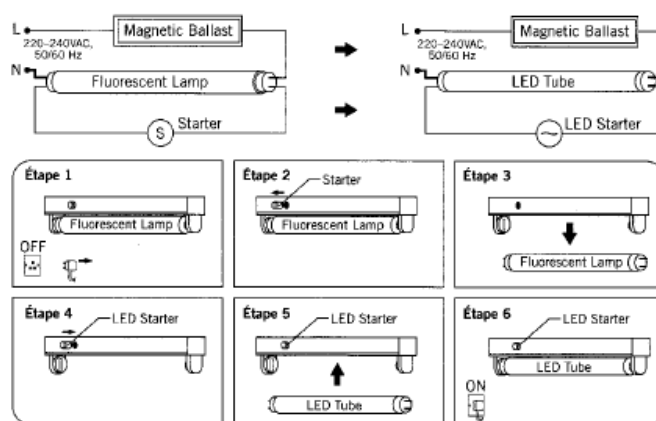

New installation / Re-wiring – Electronic Ballast Circuit

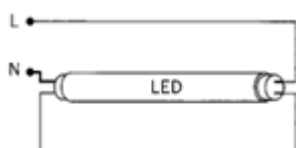

INSTALLATION :

1. Switch off the power
2. Take out the fluorescent lamp (if any)
3. Re-wiring
4. Insert the LED tube