

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, 3-position, PE-X halogen-free, black, shielded, free cable end, on Socket straight M12 SPEEDCON, coding: A, cable length: 3 m, For railway applications

Your advantages

- Easy and safe: 100 % electrically tested plug-in components
- Securely locked by special vibration brake
- Resistant to temperature influences – tested for an extended temperature range and for resistance to temperature shocks
- Reliable signal transmission – 360° shielding in environments with electromagnetic interference

Commercial data

Item number	1108343
Packing unit	1 pc
Minimum order quantity	50 pc
Sales key	*****
Product key	AF1CBA
GTIN	4063151056964
Weight per piece (including packing)	183.21 g
Weight per piece (excluding packing)	183.21 g
Customs tariff number	85444290
Country of origin	PL

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

Technical data

Notes

General	Further products with variable cable type and variable cable length can be found in the accessories section
---------	---

Product properties

Product type	Sensor/actuator cable
Application	Railway applications
Number of positions	3
No. of cable outlets	1
Shielded	yes
Coding	A

Insulation characteristics

Overvoltage category	II
Degree of pollution	3

Material specifications

Flammability rating according to UL 94	V0
Seal material	NBR
Material of grip body	PA 6.6
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	PA 6.6
Material for screw connection	Zinc die-cast, nickel-plated

Electrical properties

Nominal voltage U_N	48 V AC
	60 V DC
Nominal current I_N	4 A

Signaling

Status display	no
Status display present	No

Connection data

Conductor connection

Tightening torque	0.4 Nm
-------------------	--------

Connector

Connection 1

Type	free cable end
------	----------------

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable

1108343

<https://www.phoenixcontact.com/in/products/1108343>


Connection 2

Type	Socket straight M12 SPEEDCON
Number of positions	3
Locking type	SPEEDCON
Coding type	A

Cable/line

Cable length	3 m
--------------	-----

Shielded black RADOX® [28R]

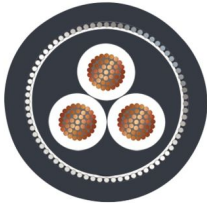Dimensional drawing	
Cable weight	51 kg/km
Number of positions	3
Shielded	yes
Cable type	Shielded black RADOX® [28R]
Conductor structure signal line	19x 0.18 mm
AWG signal line	20
Conductor cross section	3x 0.5 mm²
Wire diameter incl. insulation	1.43 mm
External cable diameter	5.30 mm ±0.3 mm
Outer sheath, material	PE-X
External sheath, color	black
Conductor material	Tin-plated Cu litz wires
Material wire insulation	PE-X
Single wire, color	white 1, white 2, white 3
Overall twist	3 wires, twisted
Max. conductor resistance	≤ 40.1 Ω/km
Nominal voltage, cable	600 V AC (Core-ground, U ₀) 1000 V AC (Core-ground, U) ≤ 720 V AC (core-ground) ≤ 1200 V AC (Core-ground, U _m) ≤ 900 V DC (Core-ground, V ₀) ≤ 1500 V DC (Line-line)
Test voltage	3500 V AC (50 Hz, 5 min.) 8400 V DC (50 Hz, 5 min.)
Minimum bending radius, fixed installation	3 x D
Minimum bending radius, flexible installation	4 x D

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

Smallest bending radius, fixed installation	16 mm
Smallest bending radius, movable installation	22 mm
Halogen-free	in accordance with EN 50267-2-1
Flame resistance	IEC 60332-1-2
	EN 50266
	EN 50305, 9.1.2
	NF C32-070, 2.1
	NF C32-070, 2.2
	UL 1685, 12 (FT4)
	in accordance with ISO 6722-1 5.22 (UN ECE-R 118.01)
Fume corrosiveness	EN 50267-2-2
Fume toxicity	BS 6853 B.1
	EN 50305, 9.2
Concentration of fumes	BS 6853 D.8.7
	EN 61034-2
	UL 1685, 12 (FT4)
Resistance to oil	according to IRM 902, 72 h at 100 °C
Fire protection in rail vehicles	BS 6853 (Category Ia, Ib, II)
	GM/RT 2130 (Category Ia, Ib, II)
	EN 45545 (Risk level HL1 - HL3)
	DIN 5510 (Fire protection level 1, 2, 3, 4)
	NF F16-101 (Category A1, A2, B)
	NF F16-101 (Class C/F0)
	NFPA 130
	UNI CEI 11170 (Risk level LR1 - LR4)
Other resistance	Resistance to fuels (according to IRM 903, 168 h at 70 °C)
Ambient temperature (operation)	-50 °C ... 120 °C (cable, fixed installation)
	-25 °C ... 90 °C (Cable, flexible installation)

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP65
	IP67
	IP68
Ambient temperature (operation)	-40 °C ... 85 °C (Plug / socket)

Standards and regulations

M12

Standard designation	M12 connector
Standards/specifications	IEC 61076-2-101
Standard designation	Shock, vibration
Standards/specifications	EN 50155


SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable

1108343

<https://www.phoenixcontact.com/in/products/1108343>


Drawings

Schematic diagram

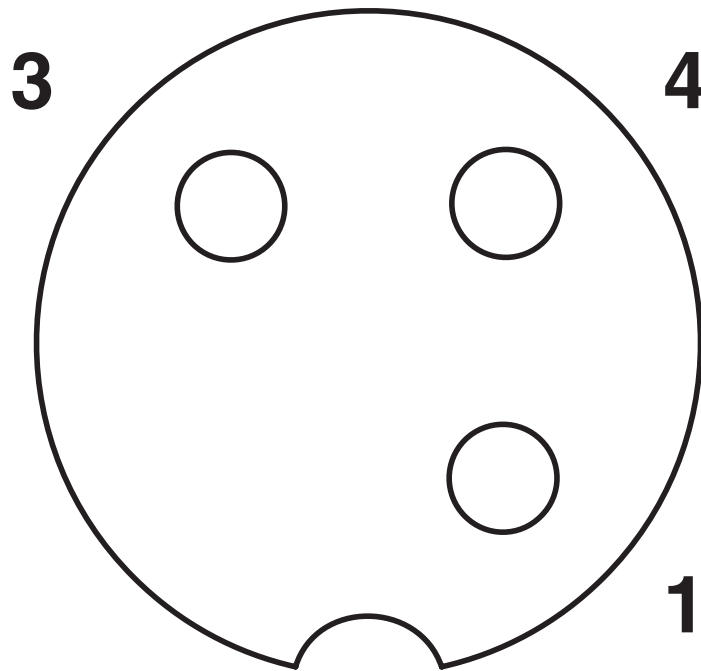

Pin assignment M12 socket, 3-pos., A-coded, view female side

Circuit diagram

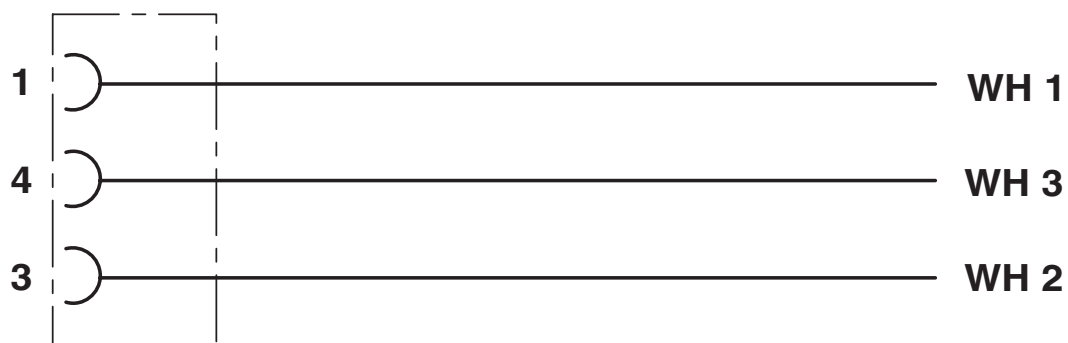


Contact assignment of the M12 socket

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable

1108343

<https://www.phoenixcontact.com/in/products/1108343>

Dimensional drawing

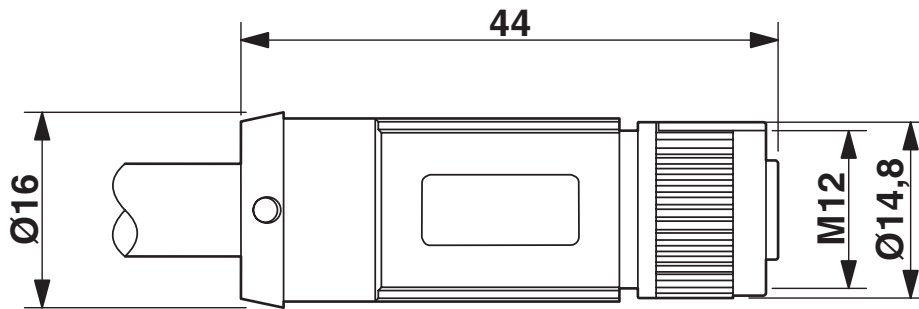

Socket M12-SPEEDCON, straight, shielded

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

Classifications

ECLASS

ECLASS-11.0	27060311
ECLASS-12.0	27060311
ECLASS-13.0	27060311

ETIM

ETIM 9.0	EC001855
----------	----------

UNSPSC

UNSPSC 21.0	26121600
-------------	----------

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol(CAS: 119-47-1)
SCIP	f3a0a3f3-c3d7-460a-8f14-009431839f44

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

Accessories

PROT-M12 MS-PA-CHAIN - Screw plug

1430899

<https://www.phoenixcontact.com/in/products/1430899>

M12 sealing cap with fixing band, for sensor cables, for free M12 sockets



SAC-M12-EXCLIP-F - Locking clip

1558991

<https://www.phoenixcontact.com/in/products/1558991>

Locking clip for the socket side of sensor/actuator cables with M12 connector and M12 connectors for assembly, for knurl diameter: 15 mm or for Allen key with a wrench size of 14 mm, prevents the disconnection of plug-in connections without tools



SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

PATG HF 3/18 - Conductor marker carrier

1014059

<https://www.phoenixcontact.com/in/products/1014059>



Conductor marker carrier, transparent/black, unlabeled, mounting type: slide-on, cable diameter range: 4 ... 7 mm, text field height: 4 mm, text field width: 18 mm

PATG HF 3/23 - Conductor marker carrier

1014060

<https://www.phoenixcontact.com/in/products/1014060>



Conductor marker carrier, transparent/black, unlabeled, mounting type: slide-on, cable diameter range: 4 ... 7 mm, text field height: 4 mm, text field width: 23 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

PATG HF 3/30 - Conductor marker carrier

1014061

<https://www.phoenixcontact.com/in/products/1014061>



Conductor marker carrier, transparent/black, unlabeled, mounting type: slide-on, cable diameter range: 4 ... 7 mm, text field height: 4 mm, text field width: 30 mm

PATG HF 4/18 - Conductor marker carrier

1014065

<https://www.phoenixcontact.com/in/products/1014065>



Conductor marker carrier, transparent/black, unlabeled, mounting type: slide-on, cable diameter range: 5 ... 10 mm, text field height: 4 mm, text field width: 18 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

PATG HF 4/23 - Conductor marker carrier

1014066

<https://www.phoenixcontact.com/in/products/1014066>



Conductor marker carrier, transparent/black, unlabeled, mounting type: slide-on, cable diameter range: 5 ... 10 mm, text field height: 4 mm, text field width: 23 mm

PATG HF 4/30 - Conductor marker carrier

1014067

<https://www.phoenixcontact.com/in/products/1014067>



Conductor marker carrier, transparent/black, unlabeled, mounting type: slide-on, cable diameter range: 5 ... 10 mm, text field height: 4 mm, text field width: 30 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable

1108343

<https://www.phoenixcontact.com/in/products/1108343>

KMK HP (25X6) - Cable marker carrier

0830720

<https://www.phoenixcontact.com/in/products/0830720>

Cable marker carrier, transparent, unlabeled, mounting type: Assembly with cable ties, cable diameter: ≥ 6 mm, text field height: 6 mm, text field width: 25 mm



KMK HP (29X8) - Cable marker carrier

0830721

<https://www.phoenixcontact.com/in/products/0830721>

Cable marker carrier, transparent, unlabeled, mounting type: Assembly with cable ties, cable diameter: ≥ 6 mm, text field height: 8 mm, text field width: 29 mm



SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

WMTB HF (40X12)R YE - Cable marker

0830408

<https://www.phoenixcontact.com/in/products/0830408>



Cable marker, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. 300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: Assembly with cable ties, cable diameter: ≥ 6 mm, Number of individual labels: 1000, text field height: 12 mm, text field width: 40 mm

WMTB HF (55X15)R YE - Cable marker

0830410

<https://www.phoenixcontact.com/in/products/0830410>



Cable marker, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. 300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: Assembly with cable ties, cable diameter: ≥ 6 mm, Number of individual labels: 1000, text field height: 15 mm, text field width: 55 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

WMTB HF (55X25)R YE - Cable marker

0830412

<https://www.phoenixcontact.com/in/products/0830412>



Cable marker, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. 300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: Assembly with cable ties, cable diameter: ≥ 6 mm, Number of individual labels: 500, text field height: 25 mm, text field width: 55 mm

WMS-2 HF 6,4 (60X10)RL YE - Shrink sleeve

0801025

<https://www.phoenixcontact.com/in/products/0801025>



Shrink sleeve, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. 300 (D)/600 (D), THERMOMARK ROLLMASTER 300/600, THERMOMARK ROLL X1, THERMOMARK ROLL, THERMOMARK ROLL 2.0, THERMOMARK W, THERMOMARK X1.2, unperforated, mounting type: slide-on, cable diameter range: 3.2 ... 6.4 mm, Number of individual labels: 1000, text field height: 10 mm, text field width: 60 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

WMS-2 HF 6,4 (EX10)RL YE - Shrink sleeve

0833244

<https://www.phoenixcontact.com/in/products/0833244>



Shrink sleeve, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. SLEEVE, THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLLMASTER 300/600, THERMOMARK ROLL X1, THERMOMARK ROLL, THERMOMARK ROLL 2.0, THERMOMARK W, THERMOMARK X1.2, unperforated, mounting type: slide-on, cable diameter range (automated processing): 3.2 ... 5 mm, cable diameter range: 3.2 ... 6.4 mm, Number of individual labels: 1, roll length: 100 m, text field height: 10 mm, text field width: 100000 mm

WMS-2 HF 9,5 (60X16)RL YE - Shrink sleeve

0801029

<https://www.phoenixcontact.com/in/products/0801029>



Shrink sleeve, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. 300 (D)/600 (D), THERMOMARK ROLLMASTER 300/600, THERMOMARK ROLL X1, THERMOMARK ROLL, THERMOMARK ROLL 2.0, THERMOMARK W, THERMOMARK X1.2, unperforated, mounting type: slide-on, cable diameter range: 4.8 ... 9.5 mm, Number of individual labels: 500, text field height: 16 mm, text field width: 60 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

WMS-2 HF 9,5 (EX16)RL YE - Shrink sleeve

0833245

<https://www.phoenixcontact.com/in/products/0833245>



Shrink sleeve, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. SLEEVE, THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLLMASTER 300/600, THERMOMARK ROLL X1, THERMOMARK ROLL, THERMOMARK ROLL 2.0, THERMOMARK W, THERMOMARK X1.2, unperforated, mounting type: slide-on, cable diameter range (automated processing): 4.8 ... 8 mm, cable diameter range: 4.8 ... 9.5 mm, Number of individual labels: 1, roll length: 80 m, text field height: 16 mm, text field width: 80000 mm

UCT-WMCO 5,4 (23X8) - Wire marking

0832105

<https://www.phoenixcontact.com/in/products/0832105>



Wire marking, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: clip on, cable diameter range: 4.7 ... 5.4 mm, Number of individual labels: 18, text field height: 8 mm, text field width: 23 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

UCT-WMCO 6,1 (23X8) - Wire marking

0832106

<https://www.phoenixcontact.com/in/products/0832106>



Wire marking, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: clip on, cable diameter range: 5.4 ... 6.1 mm, Number of individual labels: 18, text field height: 8 mm, text field width: 23 mm

UCT-WMCO 6,8 (23X8) - Wire marking

0832107

<https://www.phoenixcontact.com/in/products/0832107>



Wire marking, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: clip on, cable diameter range: 6.1 ... 6.8 mm, Number of individual labels: 15, text field height: 8 mm, text field width: 23 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

UCT-WMCO 7,5 (23X8) - Wire marking

0832108

<https://www.phoenixcontact.com/in/products/0832108>



Wire marking, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: clip on, cable diameter range: 6.8 ... 7.5 mm, Number of individual labels: 15, text field height: 8 mm, text field width: 23 mm

WMTB-AL (40X15) - Cable marker

0830524

<https://www.phoenixcontact.com/in/products/0830524>



Cable marker, Aluminum label, aluminum color, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 1, text field height: 15 mm, text field width: 40 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

WMTB-AL (60X15) - Cable marker

0830525

<https://www.phoenixcontact.com/in/products/0830525>



Cable marker, Aluminum label, aluminum color, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 1, text field height: 15 mm, text field width: 60 mm

LS-WMTB-AL (40X15) - Cable marker

0831501

<https://www.phoenixcontact.com/in/products/0831501>



Cable marker, Aluminum label, aluminum color, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 16, text field height: 15 mm, text field width: 40 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

LS-WMTB-AL (40X15) BK - Cable marker

0831509

<https://www.phoenixcontact.com/in/products/0831509>



Cable marker, Aluminum label, black, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 16, text field height: 15 mm, text field width: 40 mm

LS-WMTB-AL (60X15) - Cable marker

0831502

<https://www.phoenixcontact.com/in/products/0831502>



Cable marker, Aluminum label, aluminum color, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 16, text field height: 15 mm, text field width: 60 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

LS-WMTB-AL (60X15) BK - Cable marker

0831510

<https://www.phoenixcontact.com/in/products/0831510>



Cable marker, Aluminum label, black, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 16, text field height: 15 mm, text field width: 60 mm

LS-WMTB-AL (100X15) - Cable marker

0831503

<https://www.phoenixcontact.com/in/products/0831503>



Cable marker, Aluminum label, aluminum color, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 8, text field height: 15 mm, text field width: 100 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

LS-WMTB-AL (100X15) BK - Cable marker

0831511

<https://www.phoenixcontact.com/in/products/0831511>

Cable marker, Aluminum label, black, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, mounting type: Assembly with cable ties, cable diameter: > 4.6 mm, Number of individual labels: 8, text field height: 15 mm, text field width: 100 mm



SACC-M12MS-4QO-0,75 SH - Connector

1413993

<https://www.phoenixcontact.com/in/products/1413993>

Connector, Universal, 4-position, halogen-free, shielded, Plug straight M12, coding: A, Insulation displacement connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 5 mm ... 9.7 mm



SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

SACC-M12FS-4QO-0,75 SH - Connector

1413994

<https://www.phoenixcontact.com/in/products/1413994>



Connector, Universal, 4-position, halogen-free, shielded, Socket straight M12, coding: A, Insulation displacement connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 5 mm ... 9.7 mm

SACC-M12MS-4PL SH - Connector

1424666

<https://www.phoenixcontact.com/in/products/1424666>



Connector, Universal, 4-position, shielded, Plug straight M12, coding: A, Push-lock spring connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 4 mm ... 8 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

SACC-M12MR-4PL SH - Connector

1424667

<https://www.phoenixcontact.com/in/products/1424667>



Connector, Universal, 4-position, shielded, Plug angled M12, coding: A, Push-lock spring connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 4 mm ... 8 mm

SACC-M12FS-4PL SH - Connector

1424668

<https://www.phoenixcontact.com/in/products/1424668>



Connector, Universal, 4-position, shielded, Socket straight M12, coding: A, Push-lock spring connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 4 mm ... 8 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

SACC-M12FR-4PL SH - Connector

1424669

<https://www.phoenixcontact.com/in/products/1424669>



Connector, Universal, 4-position, shielded, Socket angled M12, coding: A, Push-lock spring connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 4 mm ... 8 mm

SACC-M12MS-5CT-CM SH - Connector

1422850

<https://www.phoenixcontact.com/in/products/1422850>



Connector, Universal, 5-position, shielded, Plug straight M12, coding: A, Crimp connection, knurl material: Zinc die-cast, tin-plated, external cable diameter 4.5 mm ... 7.5 mm, without crimp contacts

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

SACC-M12MR-5CT-CM SH - Connector

1422851

<https://www.phoenixcontact.com/in/products/1422851>



Connector, Universal, 5-position, shielded, Plug angled M12, coding: A, Crimp connection, knurl material: Zinc die-cast, tin-plated, external cable diameter 4.5 mm ... 7.5 mm, without crimp contacts

SACC-M12FS-5CT-CM SH - Connector

1422852

<https://www.phoenixcontact.com/in/products/1422852>



Connector, Universal, 5-position, shielded, Socket straight M12, coding: A, Crimp connection, knurl material: Zinc die-cast, tin-plated, external cable diameter 4.5 mm ... 7.5 mm, without crimp contacts

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

SACC-M12FR-5CT-CM SH - Connector

1422853

<https://www.phoenixcontact.com/in/products/1422853>



Connector, Universal, 5-position, shielded, Socket angled M12, coding: A, Crimp connection, knurl material: Zinc die-cast, tin-plated, external cable diameter 4.5 mm ... 7.5 mm, without crimp contacts

SACC-PO12MS-5CT-CM SH - Connector

1021815

<https://www.phoenixcontact.com/in/products/1021815>



Connector, Universal, 5-position, shielded, Plug straight M12 Push-pull external locking, coding: A, Crimp connection, knurl material: PA 6.6, external cable diameter 4.5 mm ... 7.5 mm, without crimp contacts

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

SACC-PO12MR-5CT-CM SH - Connector

1021816

<https://www.phoenixcontact.com/in/products/1021816>



Connector, Universal, 5-position, shielded, Plug angled M12 Push-pull external locking, coding: A, Crimp connection, knurl material: PA 6.6, external cable diameter 4.5 mm ... 7.5 mm, without crimp contacts

TSD 04 SAC - Torque screwdriver

1208429

<https://www.phoenixcontact.com/in/products/1208429>



Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

TSD-M 1,2NM - Torque screwdriver

1212224

<https://www.phoenixcontact.com/in/products/1212224>



Torque screw driver, accuracy as per EN ISO 6789 standard, adjustable from 0.3 - 1.2 Nm

TSD-M SAC-BIT ADAPTER - Adapter insert

1212600

<https://www.phoenixcontact.com/in/products/1212600>



Adapter bit for TSD-M...torque tools, E6.3-1/4" drive with 4 mm hexagon to accommodate SAC bits

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

SAC BIT M12-D15 - Tool

1208432

<https://www.phoenixcontact.com/in/products/1208432>



Nut for assembling sensor/actuator cables with M12 connector and M12 connectors for assembly, with a knurl diameter of 15 mm, for 4 mm hexagonal drive

B-STIFT - Marker pen

1051993

<https://www.phoenixcontact.com/in/products/1051993>



Marker pen, for manual labeling of unprinted Zack strips, smear-proof and waterproof, line thickness 0.5 mm

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

CUTFOX 12 - Cable-cutting tool

1212128

<https://www.phoenixcontact.com/in/products/1212128>



Cable cutter, for copper and aluminum up to 12 mm diameter (up to 35 mm²)

CUTFOX-S VDE - Diagonal cutter

1212207

<https://www.phoenixcontact.com/in/products/1212207>



Diagonal cutter for hard (piano wire) and soft wires, VDE 1000 V AC/1500 V DC tested

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

MICROFOX-SP-1 - Diagonal cutter

1212487

<https://www.phoenixcontact.com/in/products/1212487>



Electronic diagonal cutter, tapered head, without chamfer, with opening spring, non-reflective phosphate-treated surface, punched version

WIREFOX 4 - Stripping tool

1212156

<https://www.phoenixcontact.com/in/products/1212156>



Stripping tool, for cables and conductors (especially for rubber and silicone insulations) from 0.1 - 4 mm², self-adjusting, stripping length of up to 18 mm, cutting capacity of up to 10 mm² stranded/1.5 mm² solid, replaceable stripping blade

SAC-3P- 3,0-28R/FS SCO RAIL - Sensor/actuator cable



1108343

<https://www.phoenixcontact.com/in/products/1108343>

WIREFOX-E 4 - Stripping tool

1212704

<https://www.phoenixcontact.com/in/products/1212704>



Stripping tool, for cables and conductors (especially for rubber and silicone insulations) from 0.1 - 4 mm², self-adjusting, stripping length of up to 18 mm, cutting capacity of up to 10 mm² stranded/1.5 mm² solid, replaceable stripping blade

WIREFOX 10 - Stripping tool

1212150

<https://www.phoenixcontact.com/in/products/1212150>



Stripping tool, for cables and conductors from 0.02 - 10 mm², self-adjusting, stripping length of up to 18 mm, cutting capacity of up to 10 mm² stranded/1.5 mm² solid, replaceable stripping blade

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in