


push-in fitting QS-1/8-6-I-100

Part number: 133186

FESTO

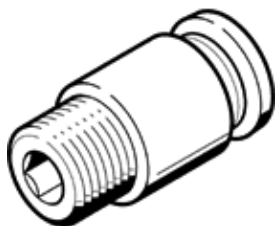

Data sheet

Feature	Value
Size	Standard
Nominal size	4.2 mm
Type of seal on screw-in stud	coating
Assembly position	Any
Container size	100
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 6 bar
Temperature dependent operating pressure	-0.95 ... 14 bar
Maritime classification	see certificate
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 80 °C
Product weight	7.6 g
Pneumatic connection, port 1	Male thread R1/8
Pneumatic connection, port 2	For tubing outside diameter 6 mm
Colour of release ring	blue
Materials note	Conforms to RoHS
Material housing	Brass Nickel plated
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive