

RACON, round plunger 11.5 mm, L 2.1 mm



fields of application

> Measurement-control-regulation

> Mechanical and system engineering

> Automotive

> Signalling systems

> Vehicle construction

> Handheld terminals

description

The wide selection of standard plungers in different shapes and colors guarantees a versatile range of applications for the RACON tactile switch.

technical data

> general

Color	white
Collar shape	round
illuminated	No
Packaging unit	500 pcs.
net weight	0.2 g
MOQ order	1,000 pcs.
RoHS compliant	Yes
REACH compliant	Yes
Component material	Plastic

> mounting diameters


Outside dimension, length	3.6 mm
Outside dimension, width	11.5 mm
Outside dimension, height	11.5 mm
Plunger length L	2.1 mm

direct links

> [RAFI eCatalog](#)

drawings

Dimensioned drawing

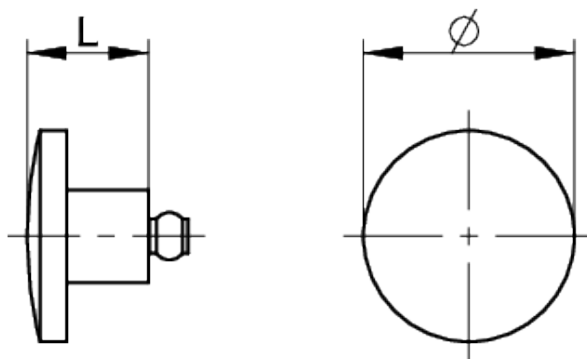

System drawing

SMT gullwing connection

Recommended: Embossing: 0.35 mm

Adhesive thickness: 0.15 mm

