


## Features

- A thicker, dual layer foam anti-fatigue mat for maximum levels of comfort.
- The new wear resistant top surface provides additional resilience against wear and tear.
- Insulates against cold concrete floors.
- Best suited to dry environments.
- Checkerplate surface provides attractive appearance.
- Ideal for demanding environments where regular turning is involved.
- Fire tested to: BS EN 13501-1 Class Cfl – s1.

## RS PRO Orthomat Black/Yellow borders 0.6m x 0.9m

RS Stock No.: 0726320

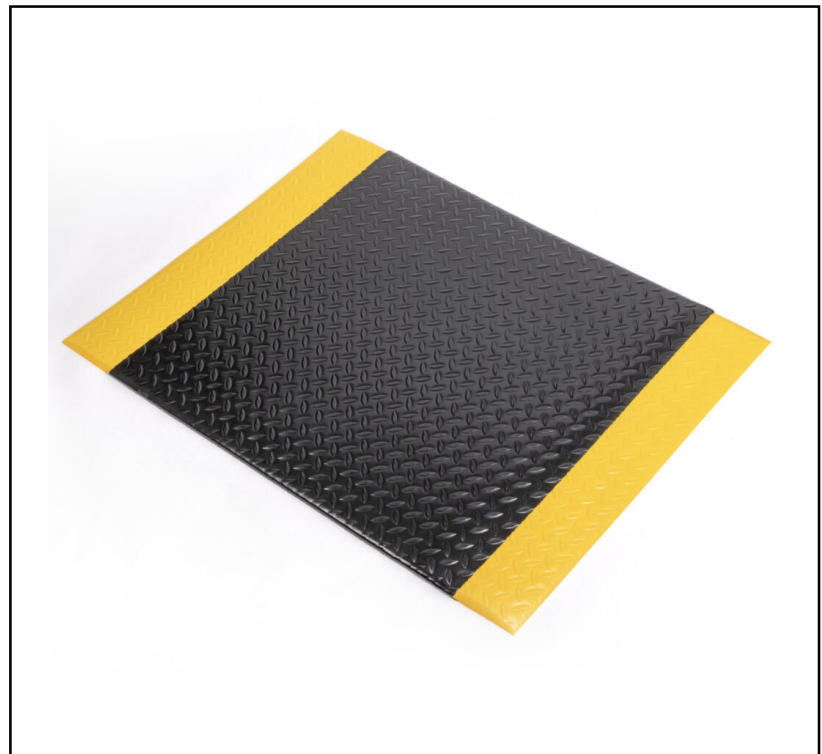

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

- These mats are engineered to deliver superior cushioning and long-lasting durability in demanding workplace environments. Featuring a **thicker, dual-layer foam construction**, are specifically designed to reduce the strain and fatigue associated with prolonged standing on hard surfaces.
- Stands out as a premium solution among anti fatigue comfort mats thanks to its:
  - **Enhanced comfort** from the thicker foam layers that relieve pressure on joints and muscles.
  - **Improved safety**, with high-visibility yellow edges and a wear-resistant top surface.
  - **Thermal insulation**, protecting workers from cold floors and improving overall wellbeing.
  - **Stylish checkerplate finish**, combining aesthetics with functionality in professional settings.
- These **anti fatigue comfort mats** are especially ideal for dry workspaces where employees need extra support—such as manufacturing lines, packing stations, and inspection areas. Choose between **standard mats or continuous rolls** for coverage that fits your specific layout.

## General Specifications

|                                   |   |
|-----------------------------------|---|
| <b>Size</b>                       | 0.6 m x 0.9 m   |
| <b>Product Height</b>             | 15 mm   |
| <b>Colour</b>                     | Black/Yellow  |
| <b>Weight (kg)</b>                | 2.25  |
| <b>Material</b>                   | Open Cell PVC foam  |
| <b>Surface Finish</b>             | Tough Checker plate surface                                     |
| <b>Min. Operating Temperature</b> | 0°C   |
| <b>Max. Operating Temperature</b> | +60°C   |
| <b>Environmental Resistance</b>   | Suitable for dry indoor environments                            |
| <b>Typical Applications</b>       | Production lines, Assembly areas, Packing stations, Workbenches |
| <b>Installation Method</b>        | Loose lay   |
| <b>Cleaning Method</b>            | Brush/mop the top surface                                       |

|                       |                              |
|-----------------------|------------------------------|
| <b>Fire Tested to</b> | BS EN 13501-1 Class Cfl - s1 |
|-----------------------|------------------------------|

## Similar Products

| Stock No. | Brand  | Product Name          | Size          | Colour       | Weight (kg) |
|-----------|--------|-----------------------|---------------|--------------|-------------|
| 0726321   | RS PRO | Orthomat Comfort Plus | 0.9 m x 1.5 m | Black/Yellow | 5.65        |