



Figure similar

SITOR cylindrical fuse link, 14x51 mm, 20 A, aR, Un AC: 690 V, Un DC: 600 V, DC according to UL, Striker indicator

Model			
product brand name		SETRON	
product designation		SITOR cylindrical fuse link	
design of the product		DC acc. to UL	
design of an identification indicator		Striker indicator	
General technical data			
operating class of the fuse link		aR	
type of voltage of the operating voltage		AC	
supply voltage at DC		600 V	
Dissipation			
power loss [W]		6 W	
power loss [W] for rated value of the current at AC in hot operating state per pole		6 W	
Main circuit			
operational current rated value		20 A	
Product details			
product component striker		Yes	
Mechanical Design			
mounting position		Any, preferably vertical	
net weight		23 g	
Approvals Certificates			
General Product Approval		other	Environment



[Confirmation](#)

[Environmental Con-
firmations](#)

Environment

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC1420-5>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NC1420-5>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC1420-5

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

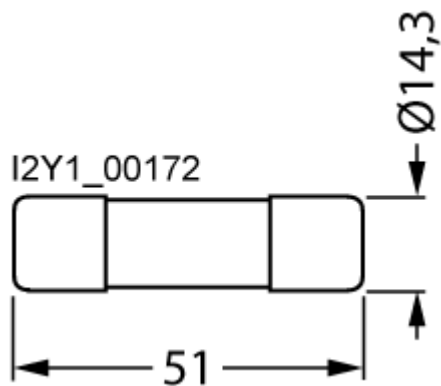

last modified:

4/11/2025 

