

## Screw connection - HC-SKV 13 MS - 1676925


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Brass screw connection, Pg13



### Key commercial data

Packing unit	10 pc
GTIN	 4 017918 129545
Weight per Piece (excluding packing)	28.63 g
Custom tariff number	85369010
Country of origin	Germany
Note	Made to Order (non-returnable)

### Technical data

#### Dimensions

Wrench size, union nut	8 mm
Wrench size, support	13 mm
External cable diameter	8 mm ... 13 mm

#### Ambient conditions

Degree of protection	IP65
	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Cable gland material	Nickel-plated brass
Shielded	No
Thread type on connection side	Pg13.5

# Screw connection - HC-SKV 13 MS - 1676925

## Classifications

### eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109

### ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000441
ETIM 5.0	EC000441

### UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

Approvals submitted

---


Approval details

EAC
-----

## Drawings

## Screw connection - HC-SKV 13 MS - 1676925

Dimensioned drawing

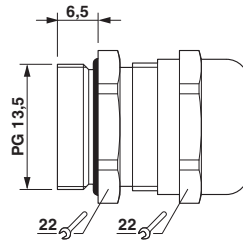

Dimensional drawing

---

Phoenix Contact 2015 © - all rights reserved  
<http://www.phoenixcontact.com>