


## Technical data sheet

**Article number:**

211-60109

H10P

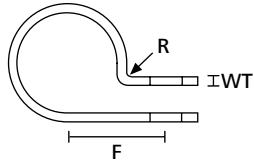

<b>Product Group</b>	Plastic P-Clamps
<b>Product Family</b>	HP-Series
<b>Material</b>	Polyamide 6.6 (PA66)
<b>Colour</b>	Natural (NA)
<b>Bundle Ø max.</b>	17.5 mm
<b>Fixation Method</b>	screw-hole
<b>Flammability</b>	UL 94 V2
<b>for Hole Ø (FH)</b>	4.2 mm
<b>Operating Temperature</b>	-40 °C to +85 °C
<b>Package Content</b>	1000 pcs.
<b>Package Content packed in</b>	pcs.
<b>Recyclate content</b>	0 %
<b>RoHS compliant</b>	Yes
<b>Specifications</b>	EN 45545-2
<b>UV-Stabilised</b>	No
<b>Variant</b>	Closed
<b>Width (W)</b>	10.0 mm

**RoHS** ✓**EN 45545-2**