


WF.SR - Non sparking wedges



Description:

- Special non sparking and anti-magnetic Copper-Beryllium alloy.

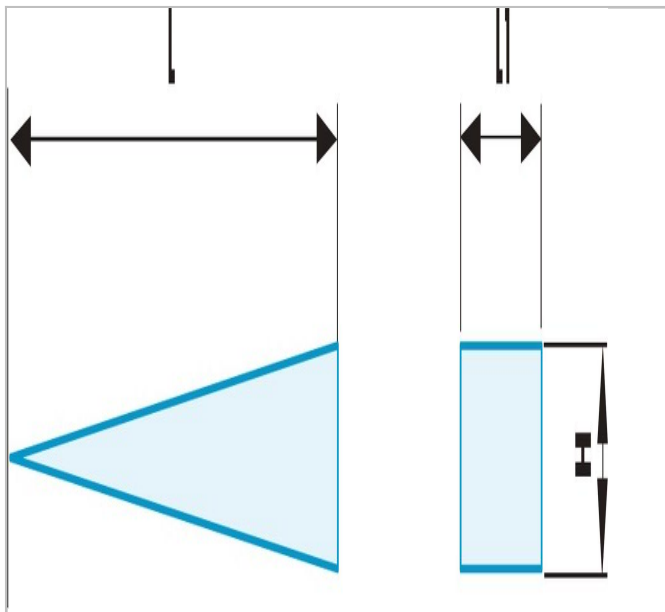

	Length L [mm]	Length L1 [mm]	Height H [mm]	Weight [g]
WF150.30SR	150.0	30.0	13.0	400.0
WF150.40SR	150.0	40.0	8.0	200.0
WF180.32SR	180.0	32.0	13.0	305.0
WF180.50SR	180.0	50.0	19.0	700.0
WF200.20SR	200.0	20.0	30.0	490.0
WF200.40SR	200.0	40.0	40.0	1300.0
WF230.40SR	230.0	40.0	20.0	750.0
WF250.40SR	250.0	40.0	30.0	1200.0
WF80.13SR	80.0	13.0	6.0	25.0