

SVS VALVE PLUG FORM A 18MM FIELD-WIREABLE



0...230V M16x1.5

Form A (18 mm) for pressure switch
0...230 V AC/DC
without components
metric


Plastic housings with good resistance against chemicals and oils. The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

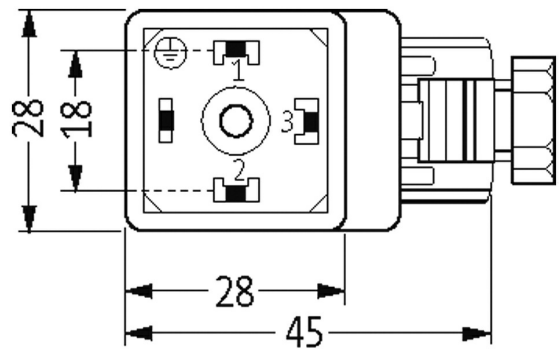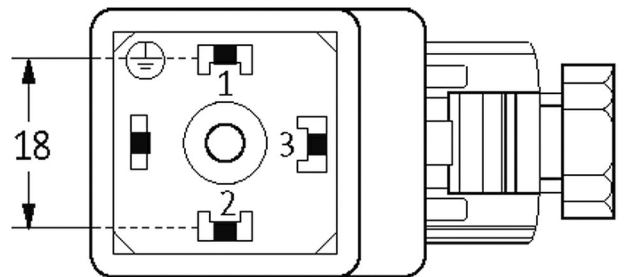

Height: 41 mm

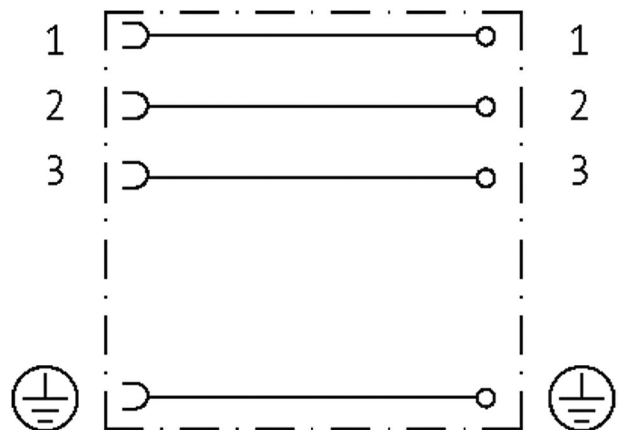

Product may differ from Image

Form

Form 29401

Technical Data

Operating voltage	max. 230 V AC/DC
Operating current per contact	max. 10 A
Configuration	3 contacts + PE
Locking of ports	M3 (recommended torque 0.4 Nm)
Protection	IP65 inserted and tightened (EN 60529)

General data

Temperature range	-20...+60 °C
-------------------	--------------

Commercial data

country of origin	CN
customs tariff number	85366990
EAN	4048879187442
eClass	27279221
Packaging unit	1