


# Solid black standard Rubber Trolley Wheel 125mm Hub 15, 130kg

Standard Rubber-tyred wheel

PRODUCT

Article number

1250515

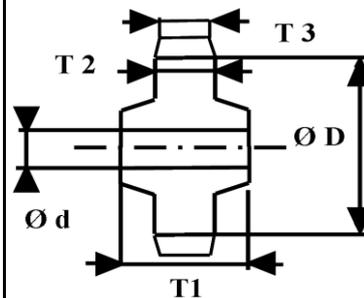

## Product Details

Wheel Rim : riveted steel plates. Bright zinc-plated protection.

Tyre : solid, black standard rubber.

Hub : symmetrical, with roller bearing.

## Specifications

Wheel Diameter - ØD ± 1%	125 mm
Hub Type	Roller bearing
Hub Length T1	45 mm ±1
Width of Tread T2	38 mm ±1
Width of Tread-on floor T3	28 mm ±1
Axle Hole Ø d	Ø 15 mm
Hardness of tread A ±4	A 82 Shore
Load capacity	130 Kg
Temperature	-20 / +60 °C
Weight	0,5 Kg

TECHNICAL DATA

## Applications :

Quiet materials handling with horizontal effort.

Resistance to tyre shedding and side impact.

Lightweight.

Suitable for trolleys on industrial floors (factory, warehouse, sack truck, ...)