



## Datasheet

ENGLISH



RS Article No. 1222793

### Specifications:


Operating Frequency	60 ops/min
Insulation Resistance	<b>&gt;100M<math>\Omega</math>@500V DC</b>
Contact Resistance	<b>&lt;25m<math>\Omega</math>(initial)</b>
Electrical Rating	10A,1/2HP 125/250VAC
Dielectric Strength	1000VAC for 1 min between current carrying parts 2500VAC for 1 min between non-current carrying parts
Service Life	Mechanically 1X10 <sup>6</sup> Electrically 5X10 <sup>5</sup>
Operating Temperature	-30~+80°C (-22~176°F)
Degree of Protection	IP68/NEMA6,6P

### Features:

- Robust glass fiber reinforce plastic body
- UL/CSA/CE/CCC Certified

10/05/2016

- Threaded hole available: M20\*1.5

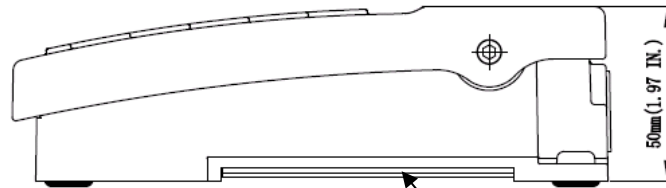

**RS PRO**  
Stock No. 1222793

