
 




ADJ700 / RR1400



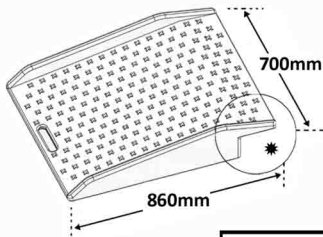


 
180kgs



	
ADJ700	
mm	860 x 700
Kgs	5.000


1T

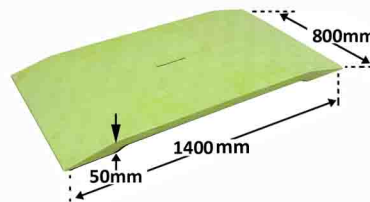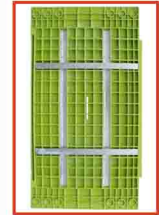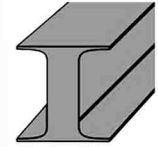


	
RR1400	
mm	1400 x 800 x 50
Kgs	22.000



RR100 / RR150 / RR200

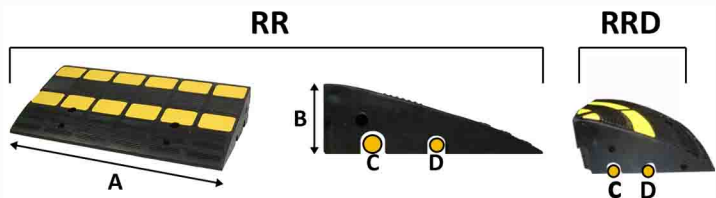

	A	B	C	D	
RR100 / RRD100	600	100	Ø30	Ø25	2xØ6 + 2xØ10 1xØ6 + 2xØ10
RR150 / RRD150	600	150	Ø35	Ø30	2xØ6 + 2xØ10 1xØ6 + 2xØ10
RR200 / RRD200	600	200	Ø40	Ø35	2xØ6 + 2xØ10 1xØ6 + 2xØ10

									
	RR100	RRD100	RR150	RRD150	RR200	RRD200	RRSIKE4SB	RRFIX4SB	RQGLUE
mm	600 x 300 x 100	300 x 300 x 100	600 x 360 x 150	360 x 360 x 150	600 x 450 x 200	450 x 450 x 200	2xØ6 + 2xØ10	2xØ6 + 2xØ10	290ml
Kgs	10.000	4.000	19.000	8.000	32.000	17.000	0.600	0.200	0.510