

## Features

- **Durable, Safe Construction** – Reinforced ABS body is non-conductive, non-sparking, and resistant to chemicals and corrosion, ideal for electrical safety.
- **Enhanced Security** – Supplied with a unique coded brass key and 6-pin cylinder for secure, tamper-resistant locking.
- **Key Retention Safety** – Jack locking mechanism ensures key cannot be removed unless the padlock is properly locked.
- **User-Friendly Grip** – Carved ribbed design allows for easy handling and use, even with gloves.
- **Clear Identification** – Includes “Danger” safety label on the front and a personnel ID label on the back for accountability.
- **Versatile Application** – Designed for both indoor and outdoor use, suitable for a wide range of electrical lockout scenarios.

## RS PRO Di-Electric Lockout Padlock with 42 mm Nylon Shackle – Key Different – Black

RS Stock No.: 0603267



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

- *ABS body features carved ribs for easy gripping and handling.*
- *Supplied with a unique coded brass key and 6-pin cylinder for increased security with different locking combinations.*
- *Jack locking key mechanism prevents key release until the shackle is closed and the padlock is locked.*
- *Reinforced ABS body is non-conductive, non-sparking, and resistant to chemicals and corrosion.*
- *Supplied with "Danger" safety label on front and personnel identification label on the back.*
- *Ideal for electrical lockout applications.*
- *Suitable for both indoor and outdoor lockout applications.*
- *Each padlock comes in a box with 1 key.*
- *Equipped with a 42 mm nylon shackle and key different operation.*

## General Specifications


|          |                                    |
|----------|------------------------------------|
| Type     | Di-electric Lockout Safety Padlock |
| Material | ABS Body with Nylon Shackle        |
| Colour   | Black                              |
| Package  | Individual box & Outer Box         |

## Mechanical Specifications

|                    |                                 |
|--------------------|---------------------------------|
| Padlock Dimensions | 42mm X 6mm X 45mm X 43mm X 20mm |
| Shackle Height     | 42mm                            |
| Shackle Dia        | 6mm                             |
| Body Height        | 45mm                            |
| Body Width         | 43mm                            |
| Body Depth         | 20mm                            |
| Weight             | 66 Grams                        |

## Operation Environment Specifications

|                       |                 |
|-----------------------|-----------------|
| Withstand temperature | -20°C to 110°C. |
|-----------------------|-----------------|

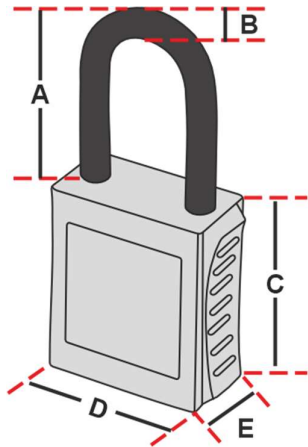

| Dimension in mm    |           |
|--------------------|-----------|
| Model              | ES-DEL-KD |
| Shackle Height (A) | 42        |
| Shackle Dia (B)    | 6         |
| Body Height (C)    | 45        |
| Body Width (D)     | 43        |
| Body Depth (E)     | 20        |