


**KEMET Part Number: SSRH24NH-40069**  
(UALS24H4006900)

KEMET, SSRH24NV/NH, AC Line Filters, Common Mode, 6900 uH

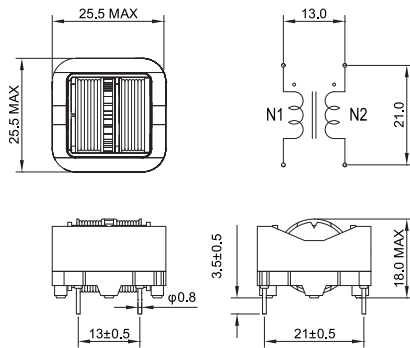

**Dimensions**

|           |                |
|-----------|----------------|
| <b>L</b>  | 25.5mm MAX     |
| <b>T</b>  | 25.5mm MAX     |
| <b>H</b>  | 18mm MAX       |
| <b>LL</b> | 3.5mm +/-0.5mm |
| <b>S</b>  | 13mm NOM       |

**Packaging Specifications**

|                            |        |
|----------------------------|--------|
| <b>Packaging:</b>          | Tray   |
| <b>Packaging Quantity:</b> | 300    |
| <b>Weight:</b>             | 22.5 g |

**General Information**

|                       |                                                           |
|-----------------------|-----------------------------------------------------------|
| <b>Series:</b>        | SSRH24NV/NH                                               |
| <b>Style:</b>         | Through-Hole                                              |
| <b>Features:</b>      | Compact Size, Light Weight, Low Rdc, Ultra-High Impedance |
| <b>RoHS:</b>          | Yes                                                       |
| <b>Miscellaneous:</b> | 65 (K) Temperature Rise Max.                              |

**Specifications**

|                           |                 |
|---------------------------|-----------------|
| <b>Voltage AC:</b>        | 250 VAC         |
| <b>Inductance:</b>        | 6.9 mH (10 kHz) |
| <b>Current:</b>           | 4 A             |
| <b>Temperature Range:</b> | -25/+120°C      |
| <b>DC Resistance:</b>     | 57 mOhms        |