

# Industrial Gland Kits

## AXT Brass Gland Kit AXT-K Series



### Application

- > Indoor/outdoor type for flexible wire braid cable (e.g CY or SY types)


### Features & Benefits

- > For circular unarmoured, or wire braid armoured or screened, plastic or rubber sheathed cables
- > Superior retention capability
- > Zero Halogen - high temperature silicone seals, LUL approved.  
Rated between -50°C and 200°C
- > IP66/IP68 seal (tested to a depth of 10m for 168 hours)
- > Improved cable range accommodation

### Technical Data

- > EN 50262
- > Quicker and easier to install
- > CuZn39Pb3 brass alloy used for guaranteed strength and performance
- > In kit form, comprising of 2 glands complete with locknut, washers, earth tag and shroud



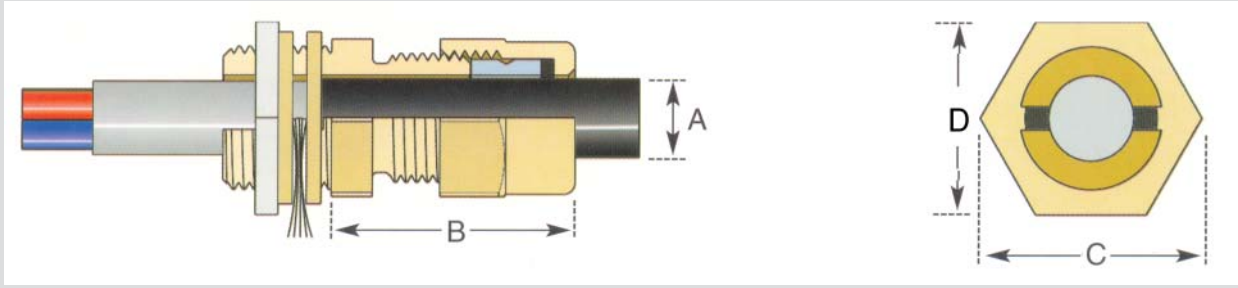

## Gland Details

Gland kit	Cable diameter A		Across Corners C mm	Protrusion Length B mm	Kit reference
	Min mm	Max mm			
20S	5.5	11.5	24.72	34.0	AXT20SK
20	8.0	16.0	28.70	44.0	AXT20K
25	11.5	21.0	36.87	46.0	AXT25K

NB. Entry Thread length = 15mm