


Data Specification Sheet

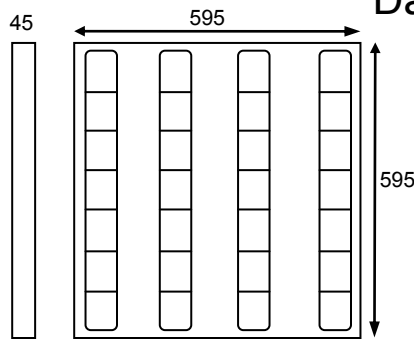

Recessed 600x600 42W LED Panel

RS Code	851-2902
Description	Recessed 42W LED modular Panel
Overall dimensions (mm)	(D)45mm (L)595mm (W)595mm
Product weight	1.6kg (c/w Driver)
Wattage	42W
Circuit Watts	43W
Lumen Output & Efficiency	3300Lm – 78Lm/W
Recommended product location	Indoor
Finishes available	White
Output Colour	4000K Cool White
Control Gear Type	Integral 1.7A 25V Driver
Dimmable	No
Lamp Supplied	Yes – Non replaceable
Class	Class I
IP	IP20
Photometric Testing	Yes
Instruction sheet	Yes
Origin of manufacture	China
Main materials:	
• Chassis	Polycarbonate
• Diffuser	4 x Mirror finish polished aluminium
Method of fix	Lay-in suitable for 600mm x 600mm recessed exposed 15mm & 25mm T ceilings.
Lamp Type	Non replaceable 4 x LED strips SMD LED
Electrical Connections	Screwless terminal block
F mark	Yes
CE mark	Yes
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details on product	Yes
Certificate of Conformity (Held on File)	Yes
Manufactured in accordance	EN60 598
Warranty	3 Years – 30,000 hour